

Reliable[®]

Streamline™ Drain Hoses

Product Description

Reliable Streamline™ Drain Hoses are intended for making fire protection system drain connections, and are available in the following nominal sizes and end configurations:

- 1" x 24" MNPT x FNPT Union
- 1-1/4" x 24" MNPT x FNPT Union
- 1-1/4" x 36" MNPT x FNPT Union
- 1-1/4" x 48" MNPT x FNPT Union
- 2" x 48" MNPT x AWWA C606 Groove

The hoses are intended for use in fire protection system drains only, and are not for use in supply piping or pressurized parts of systems.

Installation

Connect one end of the Reliable Streamline™ Drain Hose to the system main drain valve, and the opposite end of the drain piping or manifold and tighten. Avoid kinking the hose. Installation practices should be in accordance with the requirements of NFPA 13 and other applicable standards.

Maintenance

The owner is responsible for maintaining the fire protection system in proper operating condition. The Reliable Streamline™ Drain Hose shall periodically be given a thorough inspection. NFPA 25, "Inspection, Testing and Maintenance of Water Based Fire Protection Systems," provides minimum inspection and maintenance requirements.


Materials

Table A

Component	Material
Union (1-1/4")	Carbon Steel FCMB
Gasket (1-1/4")	Teflon
Corrugated Tube	STS304
Braid	STS304
Sleeve	STS304
Threaded or Grooved End Connection	Carbon Steel SPP



2" x 48" MNPT x Groove

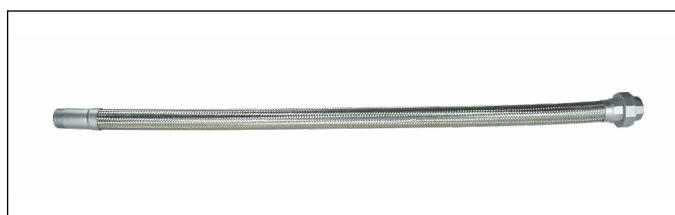

1-1/4" x 48" MNPT x FNPT Union

Note: Not all versions of the product are shown.

Guarantee

For Reliable Automatic Sprinkler Co., Inc. guarantee, terms, and conditions, visit www.reliablesprinkler.com.

Ordering Information

Specify:

Reliable Streamline™ Drain Hose

- 1" x 24" MNPT x FNPT Union
- 1-1/4" x 24" MNPT x FNPT Union
- 1-1/4" x 36" MNPT x FNPT Union
- 1-1/4" x 48" MNPT x FNPT Union
- 2" x 48" MNPT x AWWA C606 Groove