



MODEL F1 EC PENDENT

- Light Hazard (20' x 20')
- Extended Coverage
- Glass Bulb
- See Bulletin 117

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM)				
X	FECPOB	135°F 57°C	Bronze	\$ 26.96
X	FECPOC	135°F 57°C	Chrome	\$ 29.64
X	FECPOW	135°F 57°C	White	\$ 31.96
X	FECPIB	155°F 68°C	Bronze	\$ 26.96
	FECPIC	155°F 68°C	Chrome	\$ 29.64
X	FECPIW	155°F 68°C	White	\$ 31.96
17/32" ORIFICE, 3/4" NPT THREADS (20MM)				
X	FECPOLB	135°F 57°C	Bronze	\$ 29.64
X	FECPOLC	135°F 57°C	Chrome	\$ 32.33
X	FECPOLW	135°F 57°C	White	\$ 34.62
	FECPILB	155°F 68°C	Bronze	\$ 29.64
	FECPIC	155°F 68°C	Chrome	\$ 32.33
	FECPIW	155°F 68°C	White	\$ 34.75
G/F1 ESCUTCHEONS				
	GF1B	1/2" (15mm)	Brass	\$ 12.44
	GF1C	1/2" (15mm)	Chrome	\$ 6.16
	GF1W	1/2" (15mm)	White	\$ 6.16
	GF1LB	3/4" (20mm)	Brass	\$ 12.44
	GF1LC	3/4" (20mm)	Chrome	\$ 6.16
	GF1LW	3/4" (20mm)	White	\$ 6.16
X	GF1MB	10mm	Brass	\$ 11.29
	GF1MC	10mm	Chrome	\$ 6.02
X	GF1MW	10mm	White	\$ 6.02

WD	Requires Model D Sprinkler Wrench	\$	46.00
WGFR	For Recessed Use Model GFR1 Wrench	\$	178.00



MODEL F1-300 EC

PENDENT

- Light Hazard (20' x 20')
- Extended Coverage
- Glass Bulb
- See Bulletin 158


Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM) — 300 PSI				
X	FEC3P0B3	135°F 57°C	Bronze	\$ 28.92
X	FEC3P0C3	135°F 57°C	Chrome	\$ 31.71
X	FEC3P0W3	135°F 57°C	White	\$ 34.11
X	FEC3P1B3	155°F 68°C	Bronze	\$ 28.92
	FEC3P1C3	155°F 68°C	Chrome	\$ 31.71
X	FEC3P1W3	155°F 68°C	White	\$ 34.11
17/32" ORIFICE, 3/4" NPT THREADS (20MM) — 300 PSI				
X	FEC3P0LB3	135°F 57°C	Bronze	\$ 31.71
X	FEC3P0LC3	135°F 57°C	Chrome	\$ 34.48
X	FEC3P0LW3	135°F 57°C	White	\$ 36.90
	FEC3P1LB3	155°F 68°C	Bronze	\$ 31.71
	FEC3P1LC3	155°F 68°C	Chrome	\$ 34.48
	FEC3P1LW3	155°F 68°C	White	\$ 36.90
G/F1 ESCUTCHEONS				
	GF1B	1/2" (15mm)	Brass	\$ 12.44
	GF1C	1/2" (15mm)	Chrome	\$ 6.16
	GF1W	1/2" (15mm)	White	\$ 6.16
	GF1LB	3/4" (20mm)	Brass	\$ 12.44
	GF1LC	3/4" (20mm)	Chrome	\$ 6.16
	GF1LW	3/4" (20mm)	White	\$ 6.16

WD	Requires Model D Sprinkler Wrench	\$ 46.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 178.00

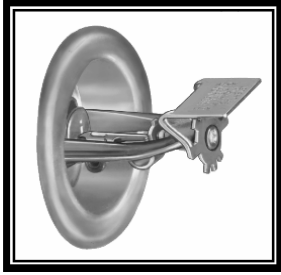

MODEL G-EC4 HSW

- Horizontal Sidewall
- Extended Coverage (16' x 24')
- See Bulletin 112

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
17/32" ORIFICE, 3/4" NPT THREADS (20MM)				
X	GEC4LB	135°F 57°C	Bronze	\$ 39.56
X	GEC4LC	135°F 57°C	Chrome	\$ 42.99
REQUIRED ESCUTCHEONS				
	GF1LB	3/4" (20mm)	Bronze	\$ 12.44
	GF1LC	3/4" (20mm)	Chrome	\$ 6.16
	GF1LW	3/4" (20mm)	White	\$ 6.16
X	GF1LSP	3/4" (20mm)	Specialty	\$ 10.84

WD	Requires Model D Sprinkler Wrench	\$ 46.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 178.00



M T O	Part Number	Temperature	Finish	List Price
SPRAY UPRIGHT 3/4" NPT (20MM)				
	GFRUV1B	165°F 74°C	Bronze	\$ 69.31
	GFRUV1C	165°F 74°C	Chrome	\$ 72.07
	GFRUV2B	212°F 100°C	Bronze	\$ 69.31
	GFRUV2C	212°F 100°C	Chrome	\$ 77.84

WH Requires Model H Sprinkler Wrench \$ 71.00

MODEL GFR VELO-ECO H

- Extended Coverage
Ordinary Hazard Upright
- Up to 400 sq. ft
- See Bulletin 165



M T O	Part Number	Temperature	Finish	List Price
SPRAY PENDENT 20' X 20'				
X	GFRPV1B	165°F 74°C	Bronze	\$ 51.56
X	GFRPV1C	165°F 74°C	Chrome	\$ 53.65
X	GFRPV1W	165°F 74°C	White	\$ 55.93
X	GFRPV2B	212°F 100°C	Bronze	\$ 51.56
X	GFRPV2C	212°F 100°C	Chrome	\$ 53.65
X	GFRPV2W	212°F 100°C	White	\$ 55.93


GFR VELO ECO H

- 14.5 K Factor, .70 Orifice, 3/4" NPT
- Coverage up to 20' x 20' - Ordinary Hazard
- See Bulletin 160

*Recessing available.

WH Requires Model H Sprinkler Wrench \$ 71.00
 WXLO Requires Model XLO Sprinkler Wrench \$ 94.00
 for Recessing

Please refer to the latest sales bulletin for specific approval listings and available finishes.
 See our "Specialties Page" for special finish charges — including Teflon Tape.
 Items that are MTO (indicated by "x") allow 7-10 work days.

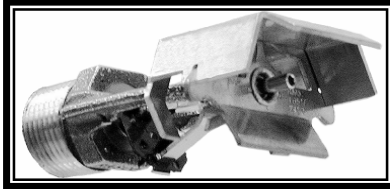

MBEC-14 HSW

- Standard Response
- Extended Coverage
- HSW
- See Bulletin 169

Horizontal Sidewall Sprinklers for Metal Building Applications!

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
MBEC-14				
	MB1B	165°F 74°C	Bronze	\$ 54.54
	MB1C	165°F 74°C	Chrome	\$ 62.56
	MB2B	212°F 100°C	Bronze	\$ 54.54
	MB2C	212°F 100°C	Chrome	\$ 62.56

WH Requires Model H Sprinkler Wrench \$ 71.00

FEATURES:

1. Designed to be installed on piping that is supported by the primary roof beams and not the purlins.
2. Provides Extended Coverage Ordinary & Extra Hazard protection.
3. Very extra large orifice of nominal K=14 permits low pressures.

IMPORTANT NOTE:

Patent Pending