





Model B-1 Accelerator

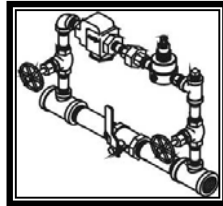

Model A-2 Air Maint. Dev

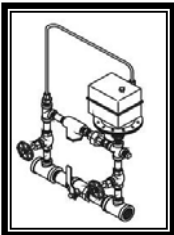

Model B-1 Air Maint. Dev

**VALVES ACCESSORIES**

- See Bulletins 250, 251, 320, 322



**NEW**

ACD Dry System Auxiliary  
Condensate Drain with Sight Glass

- See Bulletin 441


Part Name	Part Number	List Price
<b>ACCELERATOR</b>		
B1 Accelerator	AE	\$ 1,298.00
B2 Accelerator Trim	ACT	\$ 534.00
Replacement Parts Kit - B	BRPK	\$ 441.00
Replacement Parts Kit - B1	B1RPK	\$ 441.00
<b>DRY VALVE TRIM ACCESSORIES</b>		
Fill Line- Model A (2-1/2")	25FLTG	\$ 169.00
Fill Line- Model D (4 & 6")	4FLTG	\$ 169.00
Priming Chamber	PCG	\$ 295.00
<b>AIR MAINTENANCE DEVICE</b>		
A-2 Owner's Air	AMDAG	\$ 815.00
B-1 Individual Compressor	AMDBG	\$ 926.00
C Superrol Systems	AMDCG	\$ 1,222.00
<b>PRESSURE ALARM SWITCHES</b>		
EPS10-1 Alarm, Single SPDT (System Sensor)- Set 4-8PSI	EPS10-1	\$ 198.60
EPS10-2 Alarm, Double SPDT (System Sensor)- Set 4-8PSI	EPS10-2	\$ 204.70
EPS40-1 Supervisory, Single SPDT- Adj 10-100PSI	EPS40-1	\$ 187.40
EPS40-2 High/Low Supervisory Double SPDT- Adj 10-100PSI	EPS40-2	\$ 204.70
<b>VALVE SEAT WRENCHES</b>		
2-1/2" Model A Dry Pipe Valve	W4DPV	\$ 127.00
4" Model D Dry Pipe Valve	W4DPV	\$ 127.00
6" Model D Dry Pipe Valve	W6DPV	\$ 139.00

Part Name	Part Number	List Price
<b>DRY SYSTEM AUXILIARY CONDENSATE DRAIN</b>		
ACD Dry System Auxiliary Condensate Drain w- Sight Glass	ACD	\$ 450.00

Model ACD Dry System Auxiliary Condensate Drain or "Drum Drip Drain" is used in Dry Pipe and Preaction Sprinkler Systems, which meet NFPA 13 (2007) Installation Requirements section 8.16.2.5.3.4.

**Features:**

1. Sight Glass included
2. Eliminates field assembly
3. Ball Valves - quick operation
4. No assembly required
5. 1" NPT Union end connection for ease of installation
6. 1" Plug included

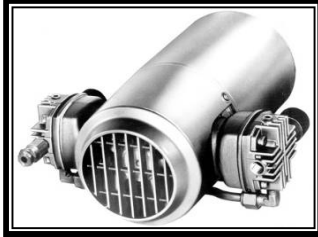

## AIR COMPRESSORS

- See Bulletin 275  
& Gast F-30

Part Name	Part Number	List Price
<b>AIR COMPRESSOR — BARE</b>		
1/6 HP, 115-60-1, Gast 1LAA-10-M100X	16A	\$ 860.00
1/4 HP, 115-60-1, Gast 2LAF-10-M200X	14A	\$ 1,000.00
1/3 HP, 115-60-1, Gast 3LBA-33-M300X	13A	\$ 1,155.00
1/2 HP, 115-60-1, Gast 4LCB-10-M450X	12A	\$ 1,555.00
3/4 HP, 115/230-60-1, Gast 5LCA-10-M550X	34A	\$ 1,615.00
3/4 HP, 230/460-60-3, Gast 5LCA-10-M553	34A3	\$ 2,000.00
1 HP, 115/230-60-1, Gast 6LCF-10-M616X	1A	\$ 2,070.00
1-1/2 HP, 115/230-60-1, Gast 7LDE-10-M700X	112A	\$ 3,434.00
2 HP, 115/230-60-1, Gast 8LDF-10-M850X	2A	\$ 4,100.00
<b>WITH CHECK VALVE AND PRESSURE SWITCH</b>		
1/6 HP, 115-60-1, Gast 1LAA-32-M100X	16PA	\$ 1,180.00
1/4 HP, 115-60-1, Gast 2LAF-12-M200X	14PA	\$ 1,385.00
1/3 HP, 115-60-1, Gast 3LBA-32-M300X	13PA	\$ 1,505.00
1/2 HP, 115-60-1, Gast 4LCB-21-M450X	12PA	\$ 1,811.00
3/4 HP, 115/230-60-1, Gast 5LCA-22-M550X	34PA	\$ 1,985.00
1 HP, 115/230-60-1, Gast 6LCF-13-M616X	1PA	\$ 2,385.00
1-1/2 HP, 115/230-60-1, Gast 7LDE-16-M750X	112PA	\$ 3,685.00
2 HP, 115/230-60-1, Gast 8LDF-16-M850X	2PA	\$ 4,665.00
<b>AIR COMPRESSORS -- TANK MOUNTED</b>		
1/6 HP, 115-60-1, Gast 1LAA-11T-M100X, 2 GAL	16TA	\$ 1,910.00
1/4 HP, 115-60-1, Gast 2LAF-11T-M200X, 12 GAL	14TA	\$ 2,485.00
1/3 HP, 115-60-1, Gast 3LBA-11T-M300X 12 GAL	13TA	\$ 2,725.00
1/2 HP, 115-60-1, Gast 4LCB-11T-M450X, 20 GAL	12TA	\$ 3,215.00
3/4 HP, 115/230-60-1, Gast 5LCA-11T-M550X, 20 GAL	34TA	\$ 3,375.00
1 HP, 115/230-60-1, Gast 6LCF-11T-M616X, 30 GAL	1TA	\$ 4,122.00
1-1/2 HP, 115/230-60-1, Gast 7LDE-11T-M750X, 30 GAL	112TA	\$ 6,200.00
2 HP, 115/230-60-1, Gast 8LDF-11TC-M850X, 30GAL	2TA	\$ 8,355.00
<b>AIR COMPRESSORS -- REPAIR KITS *</b>		
1/3 HP, Repair Kit	6888000010	\$ 275.00
3/4 HP, Repair Kit	6888000020	\$ 340.00
1-1/2 HP, Repair Kit	6888000030	\$ 670.00
Riser Mounting Brackets	6999990969	\$ 136.00

\*Repair Kit Contains Gaskets, Piston, Seals, Piston Rings, In/Out Valve Plates, Manifold Seals and Felts (for Filters)

VALVE ACCESSORIES

Part Name	Part Number	List Price
<b>PRESSURE GAUGES</b>		
Water	WATER	\$ 59.34
Air	AIR	\$ 63.43
Air (0-60 oz/in <sup>2</sup> )	98248002	\$ 224.70
<b>INSPECTORS TEST CONNECTIONS</b>		
Sight Test Type (Model B)	ISC	\$ 245.00
Blind Test Type (Model A)	IBC	\$ 82.00
<b>AUTOMATIC BALL DRIPS</b>		
1/2" NPT (Female)	78653500	\$ 142.10
3/4" NPT (Female)	78653700	\$ 162.40
<b>MECHANICAL BALL DRIPS</b>		
1/2" NPT (Female)	78653100	\$ 253.70
<b>STRAINER</b>		
3/4" NPT (Female)	78650200	\$ 149.10
<b>MISCELLANEOUS</b>		
Model C Sight Drain 2" NPT (Female)	6863000000	\$ 266.00
Model B Drum Drip Only 3/4" NPT (Female)	71010448	\$ 163.00
Model A Fill Cup 1/2" NPT (Female)	75000050	\$ 76.90
Model A Fill Cup 3/4" NPT (Female)	75000075	\$ 87.00
Model A Control Valve Seal Only	6869800000	\$ 22.00
<b>SIGNS—MODEL A</b>		
Valve Control Sign	6892011000	\$ 9.10
<b>SIGNS—MODEL B</b>		
Inspector Test Sign	ITS	\$ 3.10
Open Sprinkler Control Sign	OSCS	\$ 3.10
Open Sprinkler Drain Sign	OSDS	\$ 8.90
Test Valve Sign	TVS	\$ 3.10
Water Motor Line Sign	WMLS	\$ 3.10
Auxiliary Drain Sign	ADS	\$ 3.10
Main Drain Sign	MDS	\$ 3.10
Drain Sign	DS	\$ 3.10
Alarm Test Sign	ATS	\$ 3.10
<b>SIGNS—MODEL C</b>		
Cold Weather Sign	CWS	\$ 9.10
<b>SIGNS—MODEL D</b>		
Fire Alarm Sign	FAS	\$ 9.10
<b>SIGNS—MODEL E</b>		
Hydraulically Calculated System	HCS	\$ 9.10

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.



## NEW

Model MP (Multi-Purpose)  
Residential Riser

- See Bulletin 414

Part Name	Size	Part Num	List Price
<b>MULTI-PURPOSE RISER</b>			
Model MP	1" (30mm)	1MP	\$ 642.00
<b>RISER ACCESSORIES</b>			
Optional Support Bracket Kit		RRB	\$ 57.00

- 1" Residential Riser for providing water flow alarm on Multipurpose Residential Fire Sprinkler Systems
- cULus Listed



Residential Riser

- See Bulletin 425

Part Name	Size	Part Num	List Price
<b>RISER ASSEMBLIES</b>			
Base Unit	1" (30mm)	1RR	\$ 642.00
Base Unit and Pressure Relief Valve Trim	1" (30mm)	1RRT	\$ 931.00
Base Unit with 1 x 1/2" Test & Drain	1" (30mm)	1RRD	\$ 1,009.00
Base Unit	1-1/2" (40mm)	15RR	\$ 642.00
Base Unit and Pressure Relief Valve Trim	1-1/2" (40mm)	15RRT	\$ 931.00
Base Unit with 1 x 1/2" Test & Drain	1-1/2" (40mm)	15RRD	\$ 1,009.00
Base Unit	2" (50mm)	2RR	\$ 718.00
Base Unit and Pressure Relief Valve Trim	2" (50mm)	2RRT	\$ 1,006.00
Base Unit with 1 x 1/2" Test & Drain	2" (50mm)	2RRD	\$ 1,084.00
<b>RISER ASSEMBLIES - CANADIAN VERSION</b>			
Base Unit - Canada	1" (30mm)	1RRC	\$ 642.00
Base Unit & Pressure Relief Valve Trim - Canada	1" (30mm)	1RRTC	\$ 932.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1" (30mm)	1RRDC	\$ 1,009.00
Base Unit - Canada	1-1/2" (40mm)	15RRC	\$ 642.00
Base Unit & Pressure Relief Valve Trim - Canada	1-1/2" (40mm)	15RRTC	\$ 932.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1-1/2" (40mm)	15RRDC	\$ 1,009.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRC	\$ 718.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRTC	\$ 1,006.00
Base Unit with 1 x 1/2" Test & Drain - Canada	2" (50mm)	2RRDC	\$ 1,084.00
<b>RISER ACCESSORIES</b>			
Pressure Relief Valve Trim (good for all sizes)		15PRTC	\$ 152.00
Optional Support Bracket Kit		RRB	\$ 57.00


**Note:** Other combinations available upon request.



Model CR Commercial Riser

- For Commercial Applications
- See Bulletin 615

## NEW

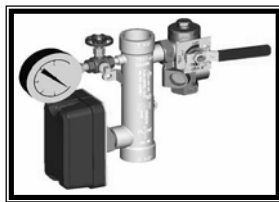

Model CR Commercial Riser with Test & Drain

- For Commercial Applications
- See Bulletin 615

Part Name	Size	Part Number	List Price
<b>COMMERCIAL RISER</b>			
Model CR Commercial Riser - Threaded	1-1/2" (40mm)	15CR	\$ 704.98
Model CR Commercial Riser - Threaded	2" (50mm)	2CR	\$ 704.98
Model CR Commercial Riser - Grooved	2" (50mm)	2CRG	\$ 704.98
Model CR Commercial Riser - Grooved	2-1/2" (65mm)	25CRG	\$ 785.76
Model CR Commercial Riser - Grooved	3" (80mm)	3CRG	\$ 822.47
Model CR Commercial Riser - Grooved	4" (100mm)	4CRG	\$ 998.71
Model CR Commercial Riser - Grooved	6" (150mm)	6CRG	\$ 1,101.52
Model CR Commercial Riser - Grooved	8" (200mm)	8CRG	\$ 1,219.01

Part Name	Size	Part Number	List Price
<b>CR COMMERCIAL RISER WITH TEST &amp; DRAIN</b>			
Model CR Commercial Riser w- Test&Drain - Threaded	1-1/2" (40mm)	15FC	\$ 954.65
Model CR Commercial Riser w- Test&Drain - Threaded	2" (50mm)	2FC	\$ 969.35
Model CR Commercial Riser w- Test&Drain - Grooved	2" (50mm)	2FCG	\$ 1,086.84
Model CR Commercial Riser w- Test&Drain - Grooved	2-1/2" (65mm)	25FC	\$ 1,145.58
Model CR Commercial Riser w- Test&Drain - Grooved	3" (80mm)	3FC	\$ 1,160.27
Model CR Commercial Riser w- Test&Drain - Grooved	4" (100mm)	4FC	\$ 1,395.27
Model CR Commercial Riser w- Test&Drain - Grooved	6" (150mm)	6FC	\$ 1,439.32
Model CR Commercial Riser w- Test&Drain - Grooved	8" (200mm)	8FC	\$ 1,615.58
<b>PRESSURE RELIEF KITS</b>			
Pressure Relief Trim - NPT	1-1/2" (40mm) - 2" (50mm)	15PRTCR	\$ 152.00
Pressure Relief Trim - Grooved End	2" (50mm)	2PRTCRG	\$ 152.00
Pressure Relief Trim - Grooved End	2-1/2" (65mm) - 3" (80mm)	25PRTCRG	\$ 152.00
Pressure Relief Trim - Grooved End	4" (150mm) - 8" (200mm)	4PRTCRG	\$ 152.00