


G

- Horizontal Sidewall
- Standard Solder Type
- See Bulletin 112

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
3/8" ORIFICE, 1/2" NPT THREADS				
X	GH03B	135°F 57°C	Bronze	\$ 35.98
X	GH03C	135°F 57°C	Chrome	\$ 39.25
X	GH13B	165°F 74°C	Bronze	\$ 35.98
X	GH13C	165°F 74°C	Chrome	\$ 39.25
X	GH23B	212°F 100°C	Bronze	\$ 35.98
X	GH23C	212°F 100°C	Chrome	\$ 39.25
X	GH33B	286°F 141°C	Bronze	\$ 35.98
X	GH33C	286°F 141°C	Chrome	\$ 39.25
7/16" ORIFICE, 1/2" NPT THREADS				
X	GH07B	135°F 57°C	Bronze	\$ 35.98
X	GH07C	135°F 57°C	Chrome	\$ 39.25
	GH17B	165°F 74°C	Bronze	\$ 35.98
X	GH17C	165°F 74°C	Chrome	\$ 39.25
X	GH27B	212°F 100°C	Bronze	\$ 35.98
	GH27C	212°F 100°C	Chrome	\$ 39.25
X	GH37B	286°F 141°C	Bronze	\$ 35.98
X	GH37C	286°F 141°C	Chrome	\$ 39.25
G/F1 ESCUTCHEONS				
	GF1B	1/2" (15mm)	Brass	\$ 13.06
	GF1C	1/2" (15mm)	Chrome	\$ 6.47
	GF1W	1/2" (15mm)	White	\$ 6.47
	GF1LB	3/4" (20mm)	Brass	\$ 13.06
	GF1LC	3/4" (20mm)	Chrome	\$ 6.47
	GF1LW	3/4" (20mm)	White	\$ 6.47
X	GF1MB	10mm	Brass	\$ 11.85
	GF1MC	10mm	Chrome	\$ 6.32
X	GF1MW	10mm	White	\$ 6.32

WD	Requires Model D Sprinkler Wrench	\$	50.00
WGFR	For Recessed Use Model GFR1 Wrench	\$	190.00

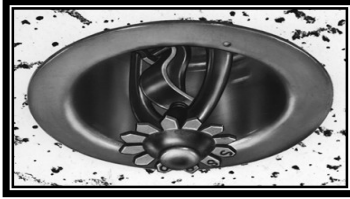

G RECESSED

- Standard Solder Type - Sprinkler Only
- Threaded Cup and Escutcheon
- See Bulletin 111

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM)— SPRINKLER ONLY				
X	GR0B	135°F 57°C	Bronze	\$ 29.94
X	GR0C	135°F 57°C	Chrome	\$ 26.90
X	GR0W	135°F 57°C	White	\$ 29.94
	GR1B	165°F 74°C	Bronze	\$ 29.94
	GR1C	165°F 74°C	Chrome	\$ 26.90
	GR1W	165°F 74°C	White	\$ 29.94
X	GR2B	212°F 100°C	Bronze	\$ 29.94
	GR2C	212°F 100°C	Chrome	\$ 26.90
X	GR2W	212°F 100°C	White	\$ 29.94
17/32" ORIFICE, 1/2" NPT THREADS (20MM) — SPRINKLER ONLY				
X	GROLHB	135°F 57°C	Bronze	\$ 36.36
X	GROLHC	135°F 57°C	Chrome	\$ 35.34
X	GR1LHB	165°F 74°C	Bronze	\$ 36.36
X	GR1LHC	165°F 74°C	Chrome	\$ 35.34
X	GR2LHB	212°F 100°C	Bronze	\$ 36.36
X	GR2LHC	212°F 100°C	Chrome	\$ 35.34
3/8" ORIFICE, 1/2" NPT THREADS — SPRINKLER ONLY				
X	GR03B	135°F 57°C	Bronze	\$ 40.73
X	GR03C	135°F 57°C	Chrome	\$ 38.66
X	GR13B	165°F 74°C	Bronze	\$ 40.73
	GR13C	165°F 74°C	Chrome	\$ 38.66
X	GR23B	212°F 100°C	Bronze	\$ 40.73
X	GR23C	212°F 100°C	Chrome	\$ 38.66
REQUIRED SPRINKLER ESCUTCHEONS				
	GRB	Threaded	Brass	\$ 16.42
	GRC	Threaded	Chrome	\$ 8.59
	GRW	Threaded	White	\$ 8.59
X	GRSP	Threaded	Specialty	\$ 16.42

WRC	Requires Model RC1 Sprinkler Wrench	\$	190.00
WFEA	For Escutcheon Use Model FEA Wrench	\$	60.00



G (CONT.)

- Recessed Pendant
- Standard Solder Type
- Sprinkler Only
- Threaded Cup
and Escutcheon
- See Bulletin 111

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
7/16" ORIFICE, 1/2" NPT THREADS — SPRINKLER ONLY				
X	GR07B	135°F 57°C	Bronze	\$ 40.73
X	GR07C	135°F 57°C	Chrome	\$ 38.66
X	GR17B	165°F 74°C	Bronze	\$ 40.73
	GR17C	165°F 74°C	Chrome	\$ 38.66
X	GR27B	212°F 100°C	Bronze	\$ 40.73
X	GR27C	212°F 100°C	Chrome	\$ 38.66
1" ADJUSTABLE MALE 1/2" ORIFICE — SPRINKLER ONLY				
X	GR0MB	135°F 57°C	Bronze	\$ 72.49
X	GR0MC	135°F 57°C	Chrome	\$ 70.42
X	GR0MW	135°F 57°C	White	\$ 72.49
X	GR1MB	165°F 74°C	Bronze	\$ 72.49
	GR1MC	165°F 74°C	Chrome	\$ 70.42
X	GR1MW	165°F 74°C	White	\$ 72.49
X	GR2MB	212°F 100°C	Bronze	\$ 72.49
X	GR2MC	212°F 100°C	Chrome	\$ 70.42
X	GR2MW	212°F 100°C	White	\$ 72.49
1" ADJUSTABLE FEMALE 1/2" ORIFICE — SPRINKLER ONLY				
X	GR0FB	135°F 57°C	Bronze	\$ 72.49
X	GR0FC	135°F 57°C	Chrome	\$ 70.42
X	GR0FW	135°F 57°C	White	\$ 72.49
X	GR1FB	165°F 74°C	Bronze	\$ 72.49
	GR1FC	165°F 74°C	Chrome	\$ 70.42
X	GR1FW	165°F 74°C	White	\$ 72.49
X	GR2FB	212°F 100°C	Bronze	\$ 72.49
X	GR2FC	212°F 100°C	Chrome	\$ 70.42
X	GR2FW	212°F 100°C	White	\$ 72.49
REQUIRED SPRINKLER ESCUTCHEONS				
	GRB	Threaded	Brass	\$ 16.42
	GRC	Threaded	Chrome	\$ 8.59
	GRW	Threaded	White	\$ 8.59
X	GRSP	Threaded	Specialty	\$ 16.42

WRC	For Recessed Use Model RC1 Wrench	\$	190.00
WFEA	For Escutcheon Use Model FEA Wrench	\$	60.00



G4 CONCEALED

- Sprinkler Only

- Adjustable Concealed
- See Bulletin 121

Sprinkler	Coverplate
135°F/57°C	135°F/57°C
165°F/74°C	165°F/74°C
212°F/100°C	165°F/74°C

Please refer to the latest sales bulletin for specific approval listings and available finishes. See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.

MTO	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM) — SPRINKLER ONLY				
	G40	135°F 57°C	Bronze	\$ 33.20
	G41	165°F 74°C	Bronze	\$ 32.21
	G42	212°F 100°C	Bronze	\$ 33.20
3/8" ORIFICE, 1/2" NPT THREADS — SPRINKLER ONLY				
X	G403	135°F 57°C	Bronze	\$ 35.43
	G413	165°F 74°C	Bronze	\$ 35.43
X	G423	212°F 100°C	Bronze	\$ 35.43
7/16" ORIFICE, 1/2" NPT THREADS — SPRINKLER ONLY				
X	G407	135°F 57°C	Bronze	\$ 35.43
X	G417	165°F 74°C	Bronze	\$ 35.43
X	G427	212°F 100°C	Bronze	\$ 35.43
1" ADJUSTABLE MALE — SPRINKLER ONLY				
X	G40M	135°F 57°C	Bronze	\$ 72.19
	G41M	165°F 74°C	Bronze	\$ 72.19
X	G42M	212°F 100°C	Bronze	\$ 72.19
1" ADJUSTABLE FEMALE — SPRINKLER ONLY				
X	G40F	135°F 57°C	Bronze	\$ 72.19
	G41F	165°F 74°C	Bronze	\$ 72.19
X	G42F	212°F 100°C	Bronze	\$ 72.19
REQUIRED COVERPLATES				
	CG40B	135°F 57°C	Bronze	\$ 31.20
	CG40C	135°F 57°C	Chrome	\$ 22.88
	CG40W	135°F 57°C	White	\$ 22.88
	CG40SP	135°F 57°C	Specialty	\$ 31.20
	CG41B	165°F 74°C	Bronze	\$ 31.20
	CG41C	165°F 74°C	Chrome	\$ 22.88
	CG41W	165°F 74°C	White	\$ 22.88
X	CG41SP	165°F 74°C	Specialty	\$ 31.20

WG4 Requires Model G4 Sprinkler Wrench \$ 189.00

Notes:

For custom finishes, customer should provide paint sample. Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.

*G1 Concealed Replacement Coverplates are on page S-97 (after Sprinkler Wrenches)



G4-300 CONCEALED

- Sprinkler Only
- Adjustable Concealed
- See Bulletin 161

Sprinkler	Coverplate
135°F/57°C	135°F/57°C
165°F/74°C	165°F/74°C
212°F/100°C	165°F/74°C

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM) — 300 PSI SPRINKLER ONLY				
	G40300	135°F 57°C	Bronze	\$ 34.39
	G41300	165°F 74°C	Bronze	\$ 34.39
	G42300	212°F 100°C	Bronze	\$ 34.39
1" ADJUSTABLE MALE — 300 PSI SPRINKLER ONLY				
X	G40M3	135°F 57°C	Bronze	\$ 75.97
	G41M3	165°F 74°C	Bronze	\$ 75.97
X	G42M3	212°F 100°C	Bronze	\$ 75.97
1" ADJUSTABLE FEMALE — 300 PSI SPRINKLER ONLY				
X	G40F3	135°F 57°C	Bronze	\$ 75.97
	G41F3	165°F 74°C	Bronze	\$ 75.97
X	G42F3	212°F 100°C	Bronze	\$ 75.97
REQUIRED COVERPLATES				
	CG40B	135°F 57°C	Bronze	\$ 31.20
	CG40C	135°F 57°C	Chrome	\$ 22.88
	CG40W	135°F 57°C	White	\$ 22.88
	CG40SP	135°F 57°C	Specialty	\$ 31.20
	CG41B	165°F 74°C	Bronze	\$ 31.20
	CG41C	165°F 74°C	Chrome	\$ 22.88
	CG41W	165°F 74°C	White	\$ 22.88
X	CG41SP	165°F 74°C	Specialty	\$ 31.20

WG4 Requires Model G4 Sprinkler Wrench \$ 189.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.



G4FR

- Adjustable Concealed
- See Bulletin 122

Sprinkler	Coverplate
165°F/74°C	135°F/57°C

M T O	Part Number	Size	Temperature		Finish	List Price
SPRINKLER ONLY						
	G4FR	1/2" x 1/2" NPT (15mm)	165°F	74°C	Bronze	\$ 34.24
	G4FR3	3/8" x 1/2" NPT	165°F	74°C	Bronze	\$ 43.31
	G4FR7	7/16" x 1/2" NPT	165°F	74°C	Bronze	\$ 43.31
	G4FRM	1" Adjust. Male	165°F	74°C	Bronze	\$ 84.22
	G4FRF	1" Adjust. Female	165°F	74°C	Bronze	\$ 84.22
REQUIRED COVERPLATES						
	CG40B	—	135°F	57°C	Bronze	\$ 31.20
	CG40C	—	135°F	57°C	Chrome	\$ 22.88
	CG40W	—	135°F	57°C	White	\$ 22.88
X	CG40SP	—	135°F	57°C	Specialty	\$ 31.20

WG4 Requires Model G4 Sprinkler Wrench

\$ 189.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.



G4 CLEANROOM

- Sealing Concealed
- Adjustable Conc. Spk. & Coverplate with Gasket
- See Bulletin 123

Sprinkler	Coverplate
135°F/57°C	135°F/57°C
165°F/74°C	135°F/57°C
212°F/100°C	165°F/74°C

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature		Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM)					
X	G4S0C	135°F	57°C	Chrome	\$ 98.42
	G4S0W	135°F	57°C	White	\$ 108.24
	G4S1C	165°F	74°C	Chrome	\$ 98.42
	G4S1W	165°F	74°C	White	\$ 98.42
	G4S2C	212°C	100°C	Chrome	\$ 98.42
	G4S2W	212°C	100°C	White	\$ 108.24
3/8" ORIFICE, 1/2" NPT THREADS					
X	G4S03C	135°F	57°C	Chrome	\$ 98.42
X	G4S03W	135°F	57°C	White	\$ 98.42
X	G4S13C	165°F	74°C	Chrome	\$ 98.42
X	G4S13W	165°F	74°C	White	\$ 98.42
X	G4S23C	212°C	100°C	Chrome	\$ 98.42
X	G4S23W	212°C	100°C	White	\$ 98.42
7/16" ORIFICE, 1/2" NPT THREADS					
X	G4S07C	135°F	57°C	Chrome	\$ 98.42
X	G4S07W	135°F	57°C	White	\$ 98.42
X	G4S17C	165°F	74°C	Chrome	\$ 98.42
X	G4S17W	165°F	74°C	White	\$ 98.42
X	G4S27C	212°C	100°C	Chrome	\$ 98.42
X	G4S27W	212°C	100°C	White	\$ 98.42
REPLACEMENT COVERPLATES & GASKET ASSEMBLY					
	CG4S0C	135°F	57°C	Chrome	\$ 31.20
	CG4S0W	135°F	57°C	White	\$ 31.20
	CG4S1C	165°F	74°C	Chrome	\$ 31.20
	CG4S1W	165°F	74°C	White	\$ 31.20

WG4 Requires Model G4 Sprinkler Wrench \$ 189.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.



G4FR CLEANROOM

- Sealing Concealed
- Adjustable Conc. Spk. & Coverplate with Gasket
- See Bulletin 123

Sprinkler	Coverplate
165°F/74°C	135°F/57°C

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM)				
	G4FRS1C	165°F 74°C	Chrome	\$ 102.32
	G4FRS1W	165°F 74°C	White	\$ 102.32
3/8" ORIFICE, 1/2" NPT THREADS				
X	G4FRS13C	165°F 74°C	Chrome	\$ 108.71
X	G4FRS13W	165°F 74°C	White	\$ 108.71
7/16" ORIFICE, 1/2" NPT THREADS				
X	G4FRS17C	165°F 74°C	Chrome	\$ 108.71
X	G4FRS17W	165°F 74°C	White	\$ 108.71
1" ADJUSTABLE — MALE				
X	G4FRS1MW	165°F 74°C	White	\$ 148.94
1" ADJUSTABLE — FEMALE				
X	G4FRS1FW	165°F 74°C	White	\$ 145.13
REPLACEMENT COVERPLATES & GASKET ASSEMBLY				
	CG4S0C	135°F 57°C	Chrome	\$ 31.20
	CG4S0W	135°F 57°C	White	\$ 31.20

WG4 Requires Model G4 Sprinkler Wrench \$ 189.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.