


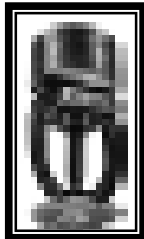

### F156 SREC

- K-Factor = 5.6 (80)
- Glass Bulb
- Thread Size = 1/2"
- See Bulletin 027

**NEW**




### F1 EC PENDENT

- Light Hazard (20' x 20')
- Extended Coverage  
- Glass Bulb
- See Bulletin 117

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
<b>1/2" ORIFICE, 1/2" NPT THREADS (15MM)</b>				
X	F56ECP0B	135°F 57°C	Bronze	\$ 31.12
X	F56ECP0C	135°F 57°C	Chrome	\$ 31.12
X	F56ECP0W	135°F 57°C	White	\$ 33.56
X	F56ECP1B	155°F 68°C	Bronze	\$ 31.12
X	F56ECP1C	155°F 68°C	Chrome	\$ 31.12
X	F56ECP1W	155°F 68°C	White	\$ 33.56
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM)</b>				
X	FECPOLB	135°F 57°C	Bronze	\$ 33.95
X	FECPOLC	135°F 57°C	Chrome	\$ 33.95
X	FECPOLW	135°F 57°C	White	\$ 36.49
	FECP1LB	155°F 68°C	Bronze	\$ 33.95
	FECP1LC	155°F 68°C	Chrome	\$ 33.95
	FECP1LW	155°F 68°C	White	\$ 36.49
<b>G/F1 ESCUTCHEONS</b>				
	GF1B	1/2" (15mm)	Brass	\$ 13.06
	GF1C	1/2" (15mm)	Chrome	\$ 6.47
	GF1W	1/2" (15mm)	White	\$ 6.47
	GF1LB	3/4" (20mm)	Brass	\$ 13.06
	GF1LC	3/4" (20mm)	Chrome	\$ 6.47
	GF1LW	3/4" (20mm)	White	\$ 6.47
X	GF1MB	10mm	Brass	\$ 11.85
	GF1MC	10mm	Chrome	\$ 6.32
X	GF1MW	10mm	White	\$ 6.32


WD	Requires Model D Sprinkler Wrench	\$ 50.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 190.00

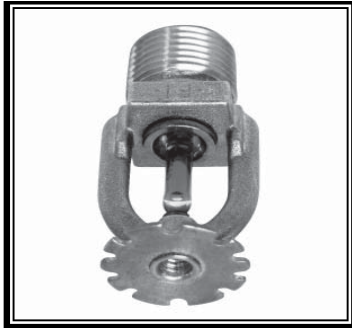

**F156-300 SREC**

- K-Factor = 5.6 (80)
- Glass Bulb
- Thread Size = 1/2"
- See Bulletin 029

**NEW**

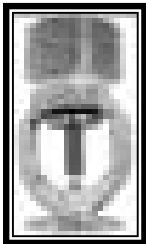


**F1-300 EC PENDENT**

- Light Hazard (20' x 20')
- Extended Coverage  
- Glass Bulb
- See Bulletin 158

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
<b>1/2" ORIFICE, 1/2" NPT THREADS (15MM) — 300 PSI</b>				
X	FEC3P0B3	135°F 57°C	Bronze	\$ 30.37
X	FEC3P0C3	135°F 57°C	Chrome	\$ 33.30
X	FEC3P0W3	135°F 57°C	White	\$ 35.82
X	FEC3P1B3	155°F 68°C	Bronze	\$ 30.37
	FEC3P1C3	155°F 68°C	Chrome	\$ 33.30
X	FEC3P1W3	155°F 68°C	White	\$ 35.82
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM) — 300 PSI</b>				
X	FEC3POLB3	135°F 57°C	Bronze	\$ 33.30
X	FEC3POLC3	135°F 57°C	Chrome	\$ 36.20
X	FEC3POLW3	135°F 57°C	White	\$ 38.75
	FEC3P1LB3	155°F 68°C	Bronze	\$ 33.30
	FEC3P1LC3	155°F 68°C	Chrome	\$ 36.20
	FEC3P1LW3	155°F 68°C	White	\$ 38.75
<b>G/F1 ESCUTCHEONS</b>				
	GF1B	1/2" (15mm)	Brass	\$ 13.06
	GF1C	1/2" (15mm)	Chrome	\$ 6.47
	GF1W	1/2" (15mm)	White	\$ 6.47
	GF1LB	3/4" (20mm)	Brass	\$ 13.06
	GF1LC	3/4" (20mm)	Chrome	\$ 6.47
	GF1LW	3/4" (20mm)	White	\$ 6.47

WD	Requires Model D Sprinkler Wrench	\$ 50.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 190.00

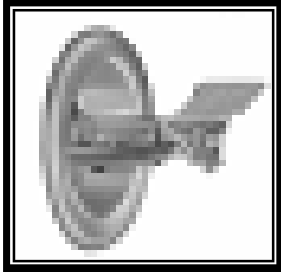


**G-EC4 HSW**

- Horizontal Sidewall
- Extended Coverage (16' x 24')
- See Bulletin 112

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM)</b>				
X	GEC4LB	135°F 57°C	Bronze	\$ 41.54
X	GEC4LC	135°F 57°C	Chrome	\$ 45.14
<b>REQUIRED ESCUTCHEONS</b>				
	GF1LB	3/4" (20mm)	Bronze	\$ 13.06
	GF1LC	3/4" (20mm)	Chrome	\$ 6.47
	GF1LW	3/4" (20mm)	White	\$ 6.47
X	GF1LSP	3/4" (20mm)	Specialty	\$ 11.38

WD	Requires Model D Sprinkler Wrench	\$ 50.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 190.00

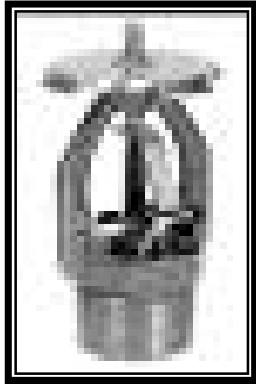


M T O	Part Number	Temperature	Finish	List Price
<b>SPRAY UPRIGHT 3/4" NPT (20MM)</b>				
	GFRUV1B	165°F 74°C	Bronze	\$ 72.78
	GFRUV1C	165°F 74°C	Chrome	\$ 75.67
	GFRUV2B	212°F 100°C	Bronze	\$ 72.78
	GFRUV2C	212°F 100°C	Chrome	\$ 81.73

WH Requires Model H Sprinkler Wrench \$ 76.00

GFR VELO-ECO H

- Extended Coverage  
Ordinary Hazard Upright
- Up to 400 sq. ft
- See Bulletin 165

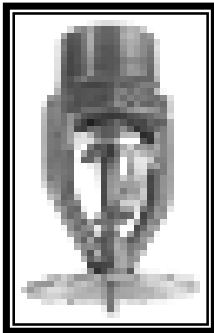

M T O	Part Number	Temperature	Finish	List Price
<b>SPRAY PENDENT 20' X 20'</b>				
X	GFRPV1B	165°F 74°C	Bronze	\$ 54.14
X	GFRPV1C	165°F 74°C	Chrome	\$ 56.33
X	GFRPV1W	165°F 74°C	White	\$ 58.73
X	GFRPV2B	212°F 100°C	Bronze	\$ 54.14
X	GFRPV2C	212°F 100°C	Chrome	\$ 56.33
X	GFRPV2W	212°F 100°C	White	\$ 58.73


GFR VELO ECO H

- 14.5 K Factor, .70 Orifice, 3/4" NPT
- Coverage up to 20' x 20' - Ordinary Hazard
- See Bulletin 160

\*Recessing available.

WH Requires Model H Sprinkler Wrench \$ 76.00  
 WXLO Requires Model XLO Sprinkler Wrench \$ 100.00  
 for Recessing

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
 See our "Specialties Page" for special finish charges — including Teflon Tape.  
 Items that are MTO (indicated by "x") allow 7-10 work days.

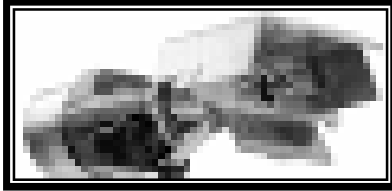

## MBEC-14 HSW

- Standard Response
- Extended Coverage
- HSW
- See Bulletin 169

### *Horizontal Sidewall Sprinklers for Metal Building Applications!*

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Temperature	Finish	List Price
<b>MBEC-14</b>				
	MB1B	165°F 74°C	Bronze	\$ 57.27
	MB1C	165°F 74°C	Chrome	\$ 65.69
	MB2B	212°F 100°C	Bronze	\$ 57.27
	MB2C	212°F 100°C	Chrome	\$ 65.69

WH Requires Model H Sprinkler Wrench \$ 76.00

### **FEATURES:**

1. Designed to be installed on piping that is supported by the primary roof beams and not the purlins.
2. Provides Extended Coverage Ordinary & Extra Hazard protection.
3. Very extra large orifice of nominal K=14 permits low pressures.

### **IMPORTANT NOTE:**

Patent Pending