



Order Matrix	
Temp/Dim	Conversions
135°F/57°C	(01)
155°F/68°C	(02)
200°F/93°C	(05)
286°F/141°C	(08)
10-1/2" Dim	1012
12-1/4" Dim	1014
6" Dim	0600

F3 PENDENT

- Standard Response Dry Sprinkler
- Replaces G3 Sprinklers
- See Bulletin 153

Note:

In white applications, sprinkler can remains chrome

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO (indicated by "X") allow 7-10 work days.

M T O	Part Number	Size	Finish	List Price
1/2" ORIFICE, 1" NPT THREADS				
X	F2[TEMP]11[DIM]	2" to 5-3/4"	Bronze	\$ 139.86
X	F2[TEMP]21[DIM]	2" to 5-3/4"	Chrome	\$ 139.86
X	F2[TEMP]08[DIM]	2" to 5-3/4"	White	\$ 143.73
X	F2[TEMP]11[DIM]	6" to 8-3/4"	Bronze	\$ 149.55
X	F2[TEMP]21[DIM]	6" to 8-3/4"	Chrome	\$ 149.55
X	F2[TEMP]08[DIM]	6" to 8-3/4"	White	\$ 153.44
X	F2[TEMP]11[DIM]	9" to 11-3/4"	Bronze	\$ 159.30
X	F2[TEMP]21[DIM]	9" to 11-3/4"	Chrome	\$ 159.30
X	F2[TEMP]08[DIM]	9" to 11-3/4"	White	\$ 163.16
X	F2[TEMP]11[DIM]	12" to 14-3/4"	Bronze	\$ 168.99
X	F2[TEMP]21[DIM]	12" to 14-3/4"	Chrome	\$ 168.99
X	F2[TEMP]08[DIM]	12" to 14-3/4"	White	\$ 172.87
X	F2[TEMP]11[DIM]	15" to 17-3/4"	Bronze	\$ 178.70
X	F2[TEMP]21[DIM]	15" to 17-3/4"	Chrome	\$ 178.70
X	F2[TEMP]08[DIM]	15" to 17-3/4"	White	\$ 182.58
X	F2[TEMP]11[DIM]	18" to 20-3/4"	Bronze	\$ 188.41
X	F2[TEMP]21[DIM]	18" to 20-3/4"	Chrome	\$ 188.41
X	F2[TEMP]08[DIM]	18" to 20-3/4"	White	\$ 192.29
X	F2[TEMP]11[DIM]	21" to 23-3/4"	Bronze	\$ 198.10
X	F2[TEMP]21[DIM]	21" to 23-3/4"	Chrome	\$ 198.10
X	F2[TEMP]08[DIM]	21" to 23-3/4"	White	\$ 201.99
X	F2[TEMP]11[DIM]	24" to 26-3/4"	Bronze	\$ 207.83
X	F2[TEMP]21[DIM]	24" to 26-3/4"	Chrome	\$ 207.83
X	F2[TEMP]08[DIM]	24" to 26-3/4"	White	\$ 211.71
X	F2[TEMP]11[DIM]	27" to 29-3/4"	Bronze	\$ 217.53
X	F2[TEMP]21[DIM]	27" to 29-3/4"	Chrome	\$ 217.53
X	F2[TEMP]08[DIM]	27" to 29-3/4"	White	\$ 221.41
X	F2[TEMP]11[DIM]	30" to 32-3/4"	Bronze	\$ 227.27
X	F2[TEMP]21[DIM]	30" to 32-3/4"	Chrome	\$ 227.27
X	F2[TEMP]08[DIM]	30" to 32-3/4"	White	\$ 231.12
X	F2[TEMP]11[DIM]	33" to 35-3/4"	Bronze	\$ 236.99
X	F2[TEMP]21[DIM]	33" to 35-3/4"	Chrome	\$ 236.99
X	F2[TEMP]08[DIM]	33" to 35-3/4"	White	\$ 240.85
X	F2[TEMP]11[DIM]	36" to 38-3/4"	Bronze	\$ 246.68
X	F2[TEMP]21[DIM]	36" to 38-3/4"	Chrome	\$ 246.68
X	F2[TEMP]08[DIM]	36" to 38-3/4"	White	\$ 250.55
X	F2[TEMP]11[DIM]	39" to 41-3/4"	Bronze	\$ 256.40
X	F2[TEMP]21[DIM]	39" to 41-3/4"	Chrome	\$ 256.40
X	F2[TEMP]08[DIM]	39" to 41-3/4"	White	\$ 260.26
X	F2[TEMP]11[DIM]	42" to 44-3/4"	Bronze	\$ 266.10
X	F2[TEMP]21[DIM]	42" to 44-3/4"	Chrome	\$ 266.10
X	F2[TEMP]08[DIM]	42" to 44-3/4"	White	\$ 269.98
X	F2[TEMP]11[DIM]	45" to 47-3/4"	Bronze	\$ 275.82
X	F2[TEMP]21[DIM]	45" to 47-3/4"	Chrome	\$ 275.82
X	F2[TEMP]08[DIM]	45" to 47-3/4"	White	\$ 279.69

***Approved "A" Dimensions Up to 48" (1219mm)**

WG3P	Required Sprinkler Wrench	\$	101.00
4003910	Dektite Pipe Flashing, 1/4" - 2"	\$	24.00



Order Matrix	
Temp/Dim	Conversions
135°F/57°C	(01)
155°F/68°C	(02)
200°F/93°C	(05)
286°F/141°C	(08)
10-1/2" Dim	1012
12-1/4" Dim	1014
6" Dim	0600

F3 REC PENDENT

- Standard Response Dry Sprinkler
- Replaces G3 Sprinklers
- See Bulletin 153

Note:

In white applications, sprinkler can remains chrome.

Please refer to the latest sales bulletin for specific approval listings and available finishes. See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.

MTO	Part Number	Size	Finish	List Price
1/2" ORIFICE, 1" NPT THREADS				
X	F6[TEMP]11[DIM]	3-1/2" to 5-3/4"	Bronze	\$ 156.37
X	F6[TEMP]21[DIM]	3-1/2" to 5-3/4"	Chrome	\$ 156.37
X	F6[TEMP]08[DIM]	3-1/2" to 5-3/4"	White	\$ 160.36
X	F6[TEMP]11[DIM]	6" to 8-3/4"	Bronze	\$ 166.36
X	F6[TEMP]21[DIM]	6" to 8-3/4"	Chrome	\$ 166.36
X	F6[TEMP]08[DIM]	6" to 8-3/4"	White	\$ 170.37
X	F6[TEMP]11[DIM]	9" to 11-3/4"	Bronze	\$ 176.37
X	F6[TEMP]21[DIM]	9" to 11-3/4"	Chrome	\$ 176.37
X	F6[TEMP]08[DIM]	9" to 11-3/4"	White	\$ 180.35
X	F6[TEMP]11[DIM]	12" to 14-3/4"	Bronze	\$ 186.34
X	F6[TEMP]21[DIM]	12" to 14-3/4"	Chrome	\$ 186.34
X	F6[TEMP]08[DIM]	12" to 14-3/4"	White	\$ 190.34
X	F6[TEMP]11[DIM]	15" to 17-3/4"	Bronze	\$ 196.36
X	F6[TEMP]21[DIM]	15" to 17-3/4"	Chrome	\$ 196.36
X	F6[TEMP]08[DIM]	15" to 17-3/4"	White	\$ 200.34
X	F6[TEMP]11[DIM]	18" to 20-3/4"	Bronze	\$ 206.36
X	F6[TEMP]21[DIM]	18" to 20-3/4"	Chrome	\$ 206.36
X	F6[TEMP]08[DIM]	18" to 20-3/4"	White	\$ 210.34
X	F6[TEMP]11[DIM]	21" to 23-3/4"	Bronze	\$ 216.35
X	F6[TEMP]21[DIM]	21" to 23-3/4"	Chrome	\$ 216.35
X	F6[TEMP]08[DIM]	21" to 23-3/4"	White	\$ 220.34
X	F6[TEMP]11[DIM]	24" to 26-3/4"	Bronze	\$ 226.33
X	F6[TEMP]21[DIM]	24" to 26-3/4"	Chrome	\$ 226.33
X	F6[TEMP]08[DIM]	24" to 26-3/4"	White	\$ 230.34
X	F6[TEMP]11[DIM]	27" to 29-3/4"	Bronze	\$ 236.34
X	F6[TEMP]21[DIM]	27" to 29-3/4"	Chrome	\$ 236.34
X	F6[TEMP]08[DIM]	27" to 29-3/4"	White	\$ 240.33
X	F6[TEMP]11[DIM]	30" to 32-3/4"	Bronze	\$ 246.34
X	F6[TEMP]21[DIM]	30" to 32-3/4"	Chrome	\$ 246.34
X	F6[TEMP]08[DIM]	30" to 32-3/4"	White	\$ 250.35
X	F6[TEMP]11[DIM]	33" to 35-3/4"	Bronze	\$ 256.35
X	F6[TEMP]21[DIM]	33" to 35-3/4"	Chrome	\$ 256.35
X	F6[TEMP]08[DIM]	33" to 35-3/4"	White	\$ 260.34
X	F6[TEMP]11[DIM]	36" to 38-3/4"	Bronze	\$ 266.94
X	F6[TEMP]21[DIM]	36" to 38-3/4"	Chrome	\$ 266.94
X	F6[TEMP]08[DIM]	36" to 38-3/4"	White	\$ 270.94
X	F6[TEMP]11[DIM]	39" to 41-3/4"	Bronze	\$ 276.96
X	F6[TEMP]21[DIM]	39" to 41-3/4"	Chrome	\$ 276.96
X	F6[TEMP]08[DIM]	39" to 41-3/4"	White	\$ 280.93
X	F6[TEMP]11[DIM]	42" to 44-3/4"	Bronze	\$ 286.94
X	F6[TEMP]21[DIM]	42" to 44-3/4"	Chrome	\$ 286.94
X	F6[TEMP]08[DIM]	42" to 44-3/4"	White	\$ 290.94
X	F6[TEMP]11[DIM]	45" to 48"	Bronze	\$ 296.93
X	F6[TEMP]21[DIM]	45" to 48"	Chrome	\$ 296.93
X	F6[TEMP]08[DIM]	45" to 48"	White	\$ 300.92
REQUIRED ESCUTCHEONS				
X	FPB1	FP PUSH-ON/THREAD-OFF	Bronze	\$ 7.29
X	FPC1	FP PUSH-ON/THREAD-OFF	Chrome	\$ 7.29
X	FPW1	FP PUSH-ON/THREAD-OFF	White	\$ 7.29

*Finish=Sprinkler and Escutcheon

WG3R	Required Sprinkler Wrench (For Recessing)	\$	190.00
4003910	Dektite Pipe Flashing, 1/4" - 2"	\$	24.00



Order Matrix	
Temp/Dim	Conversions
135°F/57°C	(01)
155°F/68°C	(02)
200°F/93°C	(05)
286°F/141°C	(08)
10-1/2" Dim	1012
12-1/4" Dim	1014
6" Dim	0600

F3 DRY HSW

- Standard Response Dry Sprinkler
- Replaces G3 Sprinklers
- See Bulletin 15c


Note:

In white applications, sprinkler can remains chrome.

Please refer to the latest sales bulletin for specific approval listings and available finishes. See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.

M T O	Part Number	Size	Finish	List Price
1/2" ORIFICE, 1" NPT THREADS				
X	F4[TEMP]11[DIM]	2" to 5-3/4"	Bronze	\$ 153.96
X	F4[TEMP]21[DIM]	2" to 5-3/4"	Chrome	\$ 153.96
X	F4[TEMP]08[DIM]	2" to 5-3/4"	White	\$ 157.97
X	F4[TEMP]11[DIM]	6" to 8-3/4"	Bronze	\$ 163.97
X	F4[TEMP]21[DIM]	6" to 8-3/4"	Chrome	\$ 163.97
X	F4[TEMP]08[DIM]	6" to 8-3/4"	White	\$ 167.95
X	F4[TEMP]11[DIM]	9" to 11-3/4"	Bronze	\$ 173.94
X	F4[TEMP]21[DIM]	9" to 11-3/4"	Chrome	\$ 173.94
X	F4[TEMP]08[DIM]	9" to 11-3/4"	White	\$ 177.93
X	F4[TEMP]11[DIM]	12" to 14-3/4"	Bronze	\$ 183.96
X	F4[TEMP]21[DIM]	12" to 14-3/4"	Chrome	\$ 183.96
X	F4[TEMP]08[DIM]	12" to 14-3/4"	White	\$ 187.95
X	F4[TEMP]11[DIM]	15" to 17-3/4"	Bronze	\$ 193.95
X	F4[TEMP]21[DIM]	15" to 17-3/4"	Chrome	\$ 193.95
X	F4[TEMP]08[DIM]	15" to 17-3/4"	White	\$ 197.97
X	F4[TEMP]11[DIM]	18" to 20-3/4"	Bronze	\$ 203.96
X	F4[TEMP]21[DIM]	18" to 20-3/4"	Chrome	\$ 203.96
X	F4[TEMP]08[DIM]	18" to 20-3/4"	White	\$ 207.93
X	F4[TEMP]11[DIM]	21" to 23-3/4"	Bronze	\$ 213.92
X	F4[TEMP]21[DIM]	21" to 23-3/4"	Chrome	\$ 213.92
X	F4[TEMP]08[DIM]	21" to 23-3/4"	White	\$ 217.96
X	F4[TEMP]11[DIM]	24" to 26-3/4"	Bronze	\$ 223.94
X	F4[TEMP]21[DIM]	24" to 26-3/4"	Chrome	\$ 223.94
X	F4[TEMP]08[DIM]	24" to 26-3/4"	White	\$ 227.92
X	F4[TEMP]11[DIM]	27" to 29-3/4"	Bronze	\$ 233.94
X	F4[TEMP]21[DIM]	27" to 29-3/4"	Chrome	\$ 233.94
X	F4[TEMP]08[DIM]	27" to 29-3/4"	White	\$ 237.94
X	F4[TEMP]11[DIM]	30" to 32-3/4"	Bronze	\$ 243.96
X	F4[TEMP]21[DIM]	30" to 32-3/4"	Chrome	\$ 243.96
X	F4[TEMP]08[DIM]	30" to 32-3/4"	White	\$ 247.94
X	F4[TEMP]11[DIM]	33" to 35-3/4"	Bronze	\$ 253.93
X	F4[TEMP]21[DIM]	33" to 35-3/4"	Chrome	\$ 253.93
X	F4[TEMP]08[DIM]	33" to 35-3/4"	White	\$ 257.94
X	F4[TEMP]11[DIM]	36" to 38-3/4"	Bronze	\$ 263.95
X	F4[TEMP]21[DIM]	36" to 38-3/4"	Chrome	\$ 263.95
X	F4[TEMP]08[DIM]	36" to 38-3/4"	White	\$ 267.94
X	F4[TEMP]11[DIM]	39" to 41-3/4"	Bronze	\$ 273.91
X	F4[TEMP]21[DIM]	39" to 41-3/4"	Chrome	\$ 273.91
X	F4[TEMP]08[DIM]	39" to 41-3/4"	White	\$ 277.95
X	F4[TEMP]11[DIM]	42" to 44-3/4"	Bronze	\$ 283.94
X	F4[TEMP]21[DIM]	42" to 44-3/4"	Chrome	\$ 283.94
X	F4[TEMP]08[DIM]	42" to 44-3/4"	White	\$ 287.91
X	F4[TEMP]11[DIM]	45" to 48"	Bronze	\$ 293.93
X	F4[TEMP]21[DIM]	45" to 48"	Chrome	\$ 293.93
X	F4[TEMP]08[DIM]	45" to 48"	White	\$ 297.92

WG3P	Required Sprinkler Wrench	\$	101.00
4003910	Dektite Pipe Flashing, 1/4" - 2"	\$	24.00

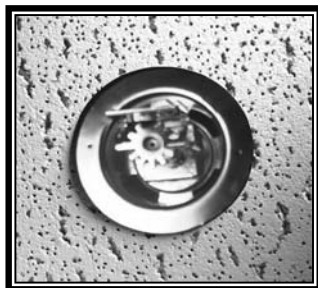

F3 DRY REC HSW

- Standard Response Dry Sprinkler
- Recessed HSW
New to F3 Line!
- See Bulletin 15:

Note:


In white applications, sprinkler can remains chrome.

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.

MTO	Part Number	Size	Finish	List Price
1/2" ORIFICE, 1" NPT THREADS				
X	F5[TEMP]11[DIM]	3-1/2" to 5-3/4"	Bronze	\$ 166.36
X	F5[TEMP]21[DIM]	3-1/2" to 5-3/4"	Chrome	\$ 166.36
X	F5[TEMP]08[DIM]	3-1/2" to 5-3/4"	White	\$ 170.37
X	F5[TEMP]11[DIM]	6" to 8-3/4"	Bronze	\$ 176.37
X	F5[TEMP]21[DIM]	6" to 8-3/4"	Chrome	\$ 176.37
X	F5[TEMP]08[DIM]	6" to 8-3/4"	White	\$ 180.35
X	F5[TEMP]11[DIM]	9" to 11-3/4"	Bronze	\$ 186.34
X	F5[TEMP]21[DIM]	9" to 11-3/4"	Chrome	\$ 186.34
X	F5[TEMP]08[DIM]	9" to 11-3/4"	White	\$ 190.34
X	F5[TEMP]11[DIM]	12" to 14-3/4"	Bronze	\$ 196.36
X	F5[TEMP]21[DIM]	12" to 14-3/4"	Chrome	\$ 196.36
X	F5[TEMP]08[DIM]	12" to 14-3/4"	White	\$ 200.34
X	F5[TEMP]11[DIM]	15" to 17-3/4"	Bronze	\$ 206.36
X	F5[TEMP]21[DIM]	15" to 17-3/4"	Chrome	\$ 206.36
X	F5[TEMP]08[DIM]	15" to 17-3/4"	White	\$ 210.34
X	F5[TEMP]11[DIM]	18" to 20-3/4"	Bronze	\$ 216.35
X	F5[TEMP]21[DIM]	18" to 20-3/4"	Chrome	\$ 216.35
X	F5[TEMP]08[DIM]	18" to 20-3/4"	White	\$ 220.34
X	F5[TEMP]11[DIM]	21" to 23-3/4"	Bronze	\$ 226.33
X	F5[TEMP]21[DIM]	21" to 23-3/4"	Chrome	\$ 226.33
X	F5[TEMP]08[DIM]	21" to 23-3/4"	White	\$ 230.34
X	F5[TEMP]11[DIM]	24" to 26-3/4"	Bronze	\$ 236.34
X	F5[TEMP]21[DIM]	24" to 26-3/4"	Chrome	\$ 236.34
X	F5[TEMP]08[DIM]	24" to 26-3/4"	White	\$ 240.33
X	F5[TEMP]11[DIM]	27" to 29-3/4"	Bronze	\$ 246.34
X	F5[TEMP]21[DIM]	27" to 29-3/4"	Chrome	\$ 246.34
X	F5[TEMP]08[DIM]	27" to 29-3/4"	White	\$ 250.35
X	F5[TEMP]11[DIM]	30" to 32-3/4"	Bronze	\$ 256.35
X	F5[TEMP]21[DIM]	30" to 32-3/4"	Chrome	\$ 256.35
X	F5[TEMP]08[DIM]	30" to 32-3/4"	White	\$ 260.34
X	F5[TEMP]11[DIM]	33" to 35-3/4"	Bronze	\$ 266.31
X	F5[TEMP]21[DIM]	33" to 35-3/4"	Chrome	\$ 266.31
X	F5[TEMP]08[DIM]	33" to 35-3/4"	White	\$ 270.33
X	F5[TEMP]11[DIM]	36" to 38-3/4"	Bronze	\$ 276.33
X	F5[TEMP]21[DIM]	36" to 38-3/4"	Chrome	\$ 276.33
X	F5[TEMP]08[DIM]	36" to 38-3/4"	White	\$ 280.32
X	F5[TEMP]11[DIM]	39" to 41-3/4"	Bronze	\$ 286.32
X	F5[TEMP]21[DIM]	39" to 41-3/4"	Chrome	\$ 286.32
X	F5[TEMP]08[DIM]	39" to 41-3/4"	White	\$ 290.34
X	F5[TEMP]11[DIM]	42" to 44-3/4"	Bronze	\$ 296.33
X	F5[TEMP]21[DIM]	42" to 44-3/4"	Chrome	\$ 296.33
X	F5[TEMP]08[DIM]	42" to 44-3/4"	White	\$ 300.32
X	F5[TEMP]11[DIM]	45" to 48"	Bronze	\$ 306.33
X	F5[TEMP]21[DIM]	45" to 48"	Chrome	\$ 306.33
X	F5[TEMP]08[DIM]	45" to 48"	White	\$ 310.33
REQUIRED ESCUTCHEONS				
X	FPB1	FP PUSH-ON/THREAD-OFF	Bronze	\$ 7.29
X	FPC1	FP PUSH-ON/THREAD-OFF	Chrome	\$ 7.29
X	FPW1	FP PUSH-ON/THREAD-OFF	White	\$ 7.29

*Finish = Sprinkler and Escutcheon

WG3R	Required Sprinkler Wrench (For Recessing)	\$	190.00
4003910	Dektite Pipe Flashing, 1/4" - 2"	\$	24.00

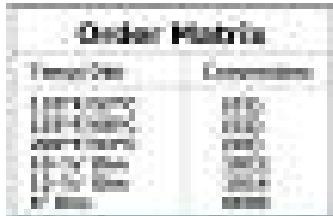

F3 CCP

- Replaces G3A Concealed
- Sprinkler Only
- See Bulletin 153

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO (indicated by "x") allow 7-10 work days.

MTO	Part Number	Size	Finish	List Price
1/2" ORIFICE, 1" NPT THREADS (15MM) — SPRINKLER & CUP				
X	FG[TEMP]17[DIM]	3-1/2" to 5-3/4"	Bronze	\$ 209.77
X	FG[TEMP]17[DIM]	6" to 8-3/4"	Bronze	\$ 219.77
X	FG[TEMP]17[DIM]	9" to 11-3/4"	Bronze	\$ 229.74
X	FG[TEMP]17[DIM]	12" to 14-3/4"	Bronze	\$ 239.74
X	FG[TEMP]17[DIM]	15" to 17-3/4"	Bronze	\$ 249.75
X	FG[TEMP]17[DIM]	18" to 20-3/4"	Bronze	\$ 259.75
X	FG[TEMP]17[DIM]	21" to 23-3/4"	Bronze	\$ 269.73
X	FG[TEMP]17[DIM]	24" to 26-3/4"	Bronze	\$ 279.92
X	FG[TEMP]17[DIM]	27" to 29-3/4"	Bronze	\$ 299.71
X	FG[TEMP]17[DIM]	30" to 32-3/4"	Bronze	\$ 319.71
X	FG[TEMP]17[DIM]	33" to 35-3/4"	Bronze	\$ 339.71
X	FG[TEMP]17[DIM]	36" to 38-3/4"	Bronze	\$ 349.71
X	FG[TEMP]17[DIM]	39" to 41-3/4"	Bronze	\$ 359.70
X	FG[TEMP]17[DIM]	42" to 44-3/4"	Bronze	\$ 369.72
X	FG[TEMP]17[DIM]	45" to 48"	Bronze	\$ 379.70
REQUIRED COVERPLATES				
	CCP0C	135°F 57°C	Chrome	\$ 21.12
	CCP0W	135°F 57°C	White	\$ 21.12
	CCP1C	165°F 74°C	Chrome	\$ 21.12
	CCP1W	165°F 74°C	White	\$ 21.12

WG3R	Required Sprinkler Wrench	\$ 190.00
4003910	Dektite Pipe Flashing, 1/4" - 2"	\$ 24.00

Notes:

Approved "A" Dimensions Up to 48" (1219mm)