


**B & FM**

- Open Sprinklers
- Window Types
- See Bulletin 103

M T O	Part Number	Size	Finish	List Price
<b>1/2" NPT THREADS (15MM)</b>				
	B4B	1/4"	Bronze	\$ 31.88
X	B5B	5/16"	Bronze	\$ 31.88
	B3B	3/8"	Bronze	\$ 31.88
<b>1/2" ORIFICE, 1/2" NPT THREADS (15MM)</b>				
X	FMWB	1/2" (15mm)	Bronze	\$ 36.55
<b>5/8", 3/4" ORIFICE, 3/4" NPT THREADS</b>				
X	FMW5B	5/8"	Bronze	\$ 38.05
X	FMW4B	3/4"	Bronze	\$ 38.05

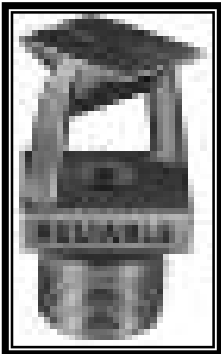

**B Cornice**


**B & FM**

- Open Sprinklers
- Cornice Types
- See Bulletin 103

M T O	Part Number	Size	Finish	List Price
<b>CORNICE TYPE MODEL FM — 1/2" ORIFICE, 1/2" NPT THREADS (15MM)</b>				
X	FMCB	1/2"	Bronze	\$ 55.63
<b>CORNICE TYPE MODEL FM — 5/8", 3/4" ORIFICE, 3/4" NPT THREADS</b>				
X	FMC5B	5/8"	Bronze	\$ 63.34
X	FMC4B	3/4"	Bronze	\$ 63.34

WD Requires Model D Sprinkler Wrench \$ 50.00


Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.

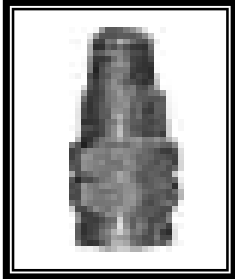

### HV SPRAY NOZZLES

- High Velocity Nozzles
- With or Without Strainer
- Bulletin 105


M T O	Part Number				Discharge Angles	Finish	List Price
	K=1.54	K=1.26	K=2.24	K = 1.82			
<b>MODEL HV-A WITHOUT STRAINER</b>							
	6999994618	—	—	—	75°	Bronze	\$ 51.00
	6999994619	—	—	—	75°	Chrome	\$ 54.09
	—	6999994622	—	—	80°	Bronze	\$ 51.00
	—	6999994623	—	—	80°	Chrome	\$ 54.09
	—	—	6999994626	—	90°	Bronze	\$ 51.00
	—	—	6999994627	—	90°	Chrome	\$ 54.09
	—	—	—	6999994630	100°	Bronze	\$ 51.00
	—	—	—	6999994631	100°	Chrome	\$ 54.09
<b>MODEL HV-AS WITH STRAINER</b>							
	6999994620	—	—	—	75°	Bronze	\$ 52.52
	6999994621	—	—	—	75°	Chrome	\$ 55.63
	—	6999994624	—	—	80°	Bronze	\$ 52.52
	—	6999994625	—	—	80°	Chrome	\$ 55.63
	—	—	6999994628	—	90°	Bronze	\$ 52.52
	—	—	6999994629	—	90°	Chrome	\$ 55.63
	—	—	—	6999994632	100°	Bronze	\$ 52.52
	—	—	—	6999994633	100°	Chrome	\$ 55.63

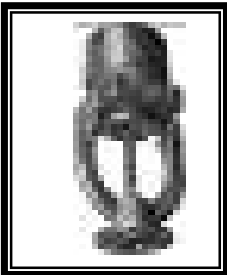

### PLD

- Upright or Pendent
- Pilot Line Detector
- Bulletin 180

M T O	Part Number	Temperature		Finish	List Price
<b>PILOT LINE DETECTOR</b>					
	PLDOB	135°F	57°C	Bronze	\$ 35.76
	PLDOC	135°F	57°C	Chrome	\$ 38.18
	PLDOW	135°F	57°C	White	\$ 40.06
	PLD1B	155°F	68°C	Bronze	\$ 35.76
	PLD1C	155°F	68°C	Chrome	\$ 38.18
	PLD1W	155°F	68°C	White	\$ 40.06
	PLD5B	175°F	79°C	Bronze	\$ 35.76
	PLD5C	175°F	79°C	Chrome	\$ 38.18
	PLD5W	175°F	79°C	White	\$ 40.06
	PLD2B	200°F	93°C	Bronze	\$ 35.76
	PLD2C	200°F	93°C	Chrome	\$ 38.18
	PLD2W	200°F	93°C	White	\$ 40.06

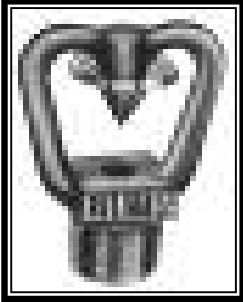

**A SPRAY NOZZLE**

- Spray Nozzles
- R20, R30, R60
- See Bulletin 106

M T O	Part Number			Angles	Finish	List Price
	R20	R30	R60			
<b>R20, R30, R60 1/2" NPT THREADS</b>						
X	R2080B	R3080B	R6080B	80°	Bronze	\$ 62.99
X	R2080C	R3080C	R6080C	80°	Chrome	\$ 62.99
X	R20110B	R30110B	R60110B	110°	Bronze	\$ 62.99
X	R20110C	R30110C	R60110C	110°	Chrome	\$ 62.99
X	R20140B	R30140B	R60140B	140°	Bronze	\$ 62.99
X	R20140C	R30140C	R60140C	140°	Chrome	\$ 62.99

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO (indicated by "x") allow 7-10 work days.