



Model B-1 Accelerator

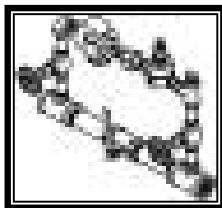


Model A-2 Air Maint. Dev

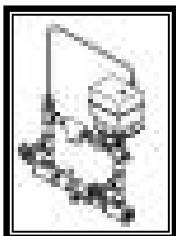

Model B-1 Air Maint. Dev

VALVES ACCESSORIES

- See Bulletins 250, 251, 320, 322

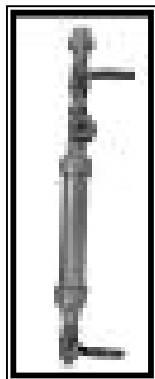

NEW

ACD Dry System Auxiliary Condensate Drain with Sight Glass

- See Bulletin 441


Part Name	Part Number	List Price
ACCELERATOR		
B1 Accelerator	AE	\$ 1,389.00
B2 Accelerator Trim	ACT	\$ 571.00
Replacement Parts Kit - B	BRPK	\$ 472.00
Replacement Parts Kit - B1	B1RPK	\$ 472.00
DRY VALVE TRIM ACCESSORIES		
Fill Line- Model A (2-1/2")	25FLTG	\$ 181.00
Fill Line- Model D (4 & 6")	4FLTG	\$ 181.00
Priming Chamber	PCG	\$ 316.00
AIR MAINTENANCE DEVICE		
A-2 Owner's Air	AMDAG	\$ 872.00
B-1 Individual Compressor	AMDBG	\$ 990.00
C Superrol Systems	AMDCG	\$ 1,307.00
PRESSURE ALARM SWITCHES		
EPS10-1 Alarm, Single SPDT (System Sensor)- Set 4-8PSI	EPS10-1	\$ 198.60
EPS10-2 Alarm, Double SPDT (System Sensor)- Set 4-8PSI	EPS10-2	\$ 204.70
EPS40-1 Supervisory, Single SPDT- Adj 10-100PSI	EPS40-1	\$ 187.40
EPS40-2 High/Low Supervisory Double SPDT- Adj 10-100PSI	EPS40-2	\$ 204.70
VALVE SEAT WRENCHES		
2-1/2" Model A Dry Pipe Valve	W4DPV	\$ 136.00
4" Model D Dry Pipe Valve	W4DPV	\$ 136.00
6" Model D Dry Pipe Valve	W6DPV	\$ 148.00

Part Name	Part Number	List Price
DRY SYSTEM AUXILIARY CONDENSATE DRAIN		
ACD Dry System Auxiliary Condensate Drain w- Sight Glass	ACD	\$ 482.00

Model ACD Dry System Auxiliary Condensate Drain or "Drum Drip Drain" is used in Dry Pipe and Preaction Sprinkler Systems, which meet NFPA 13 (2007) Installation Requirements section 8.16.2.5.3.4.

Features:

1. Sight Glass included
2. Eliminates field assembly
3. Ball Valves - quick operation
4. No assembly required
5. 1" NPT Union end connection for ease of installation
6. 1" Plug included

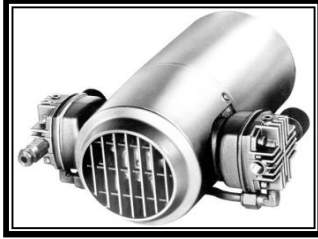

AIR COMPRESSORS

- See Bulletin 275
& Gast F-30

Part Name	Part Number	List Price
AIR COMPRESSOR — BARE		
1/6 HP, 115-60-1, Gast 1LAA-10-M100X	16A	\$ 913.58
1/4 HP, 115-60-1, Gast 2LAF-10-M200X	14A	\$ 1,056.37
1/3 HP, 115-60-1, Gast 3LBA-33-M300X	13A	\$ 1,226.25
1/2 HP, 115-60-1, Gast 4LCB-10-M450X	12A	\$ 1,646.02
3/4 HP, 115/230-60-1, Gast 5LCA-10-M550X	34A	\$ 1,711.37
3/4 HP, 230/460-60-3, Gast 5LCA-10-M553	34A3	\$ 2,121.50
1 HP, 115/230-60-1, Gast 6LCF-10-M616X	1A	\$ 2,184.52
1-1/2 HP, 115/230-60-1, Gast 7LDE-10-M700X	112A	\$ 3,644.37
2 HP, 115/230-60-1, Gast 8LDF-10-M850X	2A	\$ 4,311.72
WITH CHECK VALVE AND PRESSURE SWITCH		
1/6 HP, 115-60-1, Gast 1LAA-32-M100X	16PA	\$ 1,342.70
1/4 HP, 115-60-1, Gast 2LAF-12-M200X	14PA	\$ 1,461.91
1/3 HP, 115-60-1, Gast 3LBA-32-M300X	13PA	\$ 1,698.04
1/2 HP, 115-60-1, Gast 4LCB-21-M450X	12PA	\$ 2,024.28
3/4 HP, 115/230-60-1, Gast 5LCA-22-M550X	34PA	\$ 2,192.57
1 HP, 115/230-60-1, Gast 6LCF-13-M616X	1PA	\$ 2,617.10
1-1/2 HP, 115/230-60-1, Gast 7LDE-16-M750X	112PA	\$ 4,005.00
2 HP, 115/230-60-1, Gast 8LDF-16-M850X	2PA	\$ 4,900.90
AIR COMPRESSORS -- TANK MOUNTED		
1/6 HP, 115-60-1, Gast 1LAA-11T-M100X, 2 GAL	16TA	\$ 2,023.29
1/4 HP, 115-60-1, Gast 2LAF-11T-M200X, 12 GAL	14TA	\$ 2,616.35
1/3 HP, 115-60-1, Gast 3LBA-11T-M300X 12 GAL	13TA	\$ 2,868.53
1/2 HP, 115-60-1, Gast 4LCB-11T-M450X, 20 GAL	12TA	\$ 3,410.16
3/4 HP, 115/230-60-1, Gast 5LCA-11T-M550X, 20 GAL	34TA	\$ 3,586.73
1 HP, 115/230-60-1, Gast 6LCF-11T-M616X, 30 GAL	1TA	\$ 4,359.82
1-1/2 HP, 115/230-60-1, Gast 7LDE-11T-M750X, 30 GAL	112TA	\$ 6,510.65
2 HP, 115/230-60-1, Gast 8LDF-11TC-M850X, 30GAL	2TA	\$ 8,809.84
AIR COMPRESSORS -- REPAIR KITS *		
1/3 HP, Repair Kit	6888000010	\$ 275.00
3/4 HP, Repair Kit	6888000020	\$ 340.00
1-1/2 HP, Repair Kit	6888000030	\$ 564.80
Riser Mounting Brackets	6999990969	\$ 136.00


*Repair Kit Contains Gaskets, Piston, Seals, Piston Rings, In/Out Valve Plates, Manifold Seals and Felts (for Filters)

VALVE ACCESSORIES

Part Name	Part Number	List Price
PRESSURE GAUGES		
Water	WATER	\$ 63.49
Air	AIR	\$ 67.87
Air (0-60 oz/in ²)	98248002	\$ 240.43
INSPECTORS TEST CONNECTIONS		
Sight Test Type (Model B)	ISC	\$ 262.00
Blind Test Type (Model A)	IBC	\$ 88.00
AUTOMATIC BALL DRIPS		
1/2" NPT (Female)	78653500	\$ 152.10
3/4" NPT (Female)	78653700	\$ 173.80
MECHANICAL BALL DRIPS		
1/2" NPT (Female)	78653100	\$ 271.50
STRAINER		
3/4" NPT (Female)	78650200	\$ 159.60
MISCELLANEOUS		
Model C Sight Drain 2" NPT (Female)	6863000000	\$ 285.00
Model B Drum Drip Only 3/4" NPT (Female)	71010448	\$ 175.00
Model A Fill Cup 1/2" NPT (Female)	75000050	\$ 82.30
Model A Fill Cup 3/4" NPT (Female)	75000075	\$ 93.10
Model A Control Valve Seal Only	6869800000	\$ 23.00
SIGNS—MODEL A		
Valve Control Sign	6892011000	\$ 11.80
SIGNS—MODEL B		
Inspector Test Sign	ITS	\$ 2.30
Open Sprinkler Control Sign	OSCS	\$ 2.50
Open Sprinkler Drain Sign	OSDS	\$ 2.50
Test Valve Sign	TVS	\$ 2.50
Water Motor Line Sign	WMLS	\$ 2.50
Auxiliary Drain Sign	ADS	\$ 2.30
Main Drain Sign	MDS	\$ 2.30
Drain Sign	DS	\$ 2.20
Alarm Test Sign	ATS	\$ 2.50
SIGNS—MODEL C		
Cold Weather Sign	CWS	\$ 9.80
SIGNS—MODEL D		
Fire Alarm Sign	FAS	\$ 11.80
SIGNS—MODEL E		
Hydraulically Calculated System	HCS	\$ 6.50

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO (indicated by "x") allow 7-10 work days.

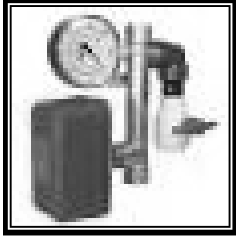


NEW

Model MP (Multi-Purpose)
Residential Riser

- See Bulletin 414

Part Name	Size	Part Num	List Price
MULTI-PURPOSE RISER			
Model MP	1" (30mm)	1MP	\$ 687.00
RISER ACCESSORIES			
Optional Support Bracket Kit		RRB	\$ 61.00

- 1" Residential Riser for providing water flow alarm on Multipurpose Residential Fire Sprinkler Systems
- cULus Listed

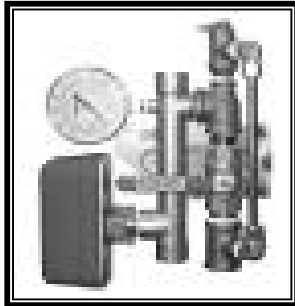


Residential Riser

- See Bulletin 425

Part Name	Size	Part Num	List Price
RISER ASSEMBLIES			
Base Unit	1" (30mm)	1RR	\$ 687.00
Base Unit and Pressure Relief Valve Trim	1" (30mm)	1RRT	\$ 996.00
Base Unit with 1 x 1/2" Test & Drain	1" (30mm)	1RRD	\$ 1,079.00
Base Unit	1-1/2" (40mm)	15RR	\$ 687.00
Base Unit and Pressure Relief Valve Trim	1-1/2" (40mm)	15RRT	\$ 996.00
Base Unit with 1 x 1/2" Test & Drain	1-1/2" (40mm)	15RRD	\$ 1,079.00
Base Unit	2" (50mm)	2RR	\$ 768.00
Base Unit and Pressure Relief Valve Trim	2" (50mm)	2RRT	\$ 1,077.00
Base Unit with 1 x 1/2" Test & Drain	2" (50mm)	2RRD	\$ 1,160.00
RISER ASSEMBLIES - CANADIAN VERSION			
Base Unit - Canada	1" (30mm)	1RRC	\$ 687.00
Base Unit & Pressure Relief Valve Trim - Canada	1" (30mm)	1RRTC	\$ 997.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1" (30mm)	1RRDC	\$ 1,079.00
Base Unit - Canada	1-1/2" (40mm)	15RRC	\$ 687.00
Base Unit & Pressure Relief Valve Trim - Canada	1-1/2" (40mm)	15RRTC	\$ 997.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1-1/2" (40mm)	15RRDC	\$ 1,079.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRC	\$ 768.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRTC	\$ 1,077.00
Base Unit with 1 x 1/2" Test & Drain - Canada	2" (50mm)	2RRDC	\$ 1,160.00
RISER ACCESSORIES			
Pressure Relief Valve Trim (good for all sizes)		15PRTCR	\$ 162.00
Optional Support Bracket Kit		RRB	\$ 61.00


Note: Other combinations available upon request.

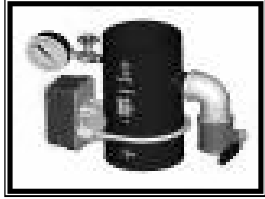

Model CR Commercial Riser

- For Commercial Applications
- See Bulletin 615

NEW

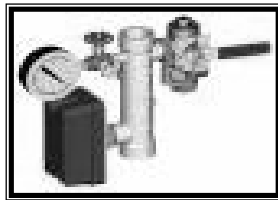

Model CR Commercial Riser with Test & Drain

- For Commercial Applications
- See Bulletin 615

Part Name	Size	Part Number	List Price
COMMERCIAL RISER			
Model CR Commercial Riser - Threaded	1-1/2" (40mm)	15CR	\$ 754.33
Model CR Commercial Riser - Threaded	2" (50mm)	2CR	\$ 754.33
Model CR Commercial Riser - Grooved	2" (50mm)	2CRG	\$ 754.33
Model CR Commercial Riser - Grooved	2-1/2" (65mm)	25CRG	\$ 840.76
Model CR Commercial Riser - Grooved	3" (80mm)	3CRG	\$ 880.04
Model CR Commercial Riser - Grooved	4" (100mm)	4CRG	\$ 1,068.62
Model CR Commercial Riser - Grooved	6" (150mm)	6CRG	\$ 1,178.63
Model CR Commercial Riser - Grooved	8" (200mm)	8CRG	\$ 1,304.34

Part Name	Size	Part Number	List Price
CR COMMERCIAL RISER WITH TEST & DRAIN			
Model CR Commercial Riser w- Test&Drain - Threaded	1-1/2" (40mm)	15FC	\$ 1,021.48
Model CR Commercial Riser w- Test&Drain - Threaded	2" (50mm)	2FC	\$ 1,037.20
Model CR Commercial Riser w- Test&Drain - Grooved	2" (50mm)	2FCG	\$ 1,162.92
Model CR Commercial Riser w- Test&Drain - Grooved	2-1/2" (65mm)	25FC	\$ 1,225.77
Model CR Commercial Riser w- Test&Drain - Grooved	3" (80mm)	3FC	\$ 1,241.49
Model CR Commercial Riser w- Test&Drain - Grooved	4" (100mm)	4FC	\$ 1,492.94
Model CR Commercial Riser w- Test&Drain - Grooved	6" (150mm)	6FC	\$ 1,540.07
Model CR Commercial Riser w- Test&Drain - Grooved	8" (200mm)	8FC	\$ 1,728.67
PRESSURE RELIEF KITS			
Pressure Relief Trim - NPT	1-1/2" (40mm) - 2" (50mm)	15PRTCR	\$ 162.00
Pressure Relief Trim - Grooved End	2" (50mm)	2PRTCRG	\$ 162.00
Pressure Relief Trim - Grooved End	2-1/2" (65mm) - 3" (80mm)	25PRTCRG	\$ 162.00
Pressure Relief Trim - Grooved End	4" (150mm) - 8" (200mm)	4PRTCRG	\$ 286.00