


B & FM SPRAY NOZZLES

- Open Sprinklers
- Window Types
- See Bulletin 103

Part Number	Size	Finish	List Price
1/2" NPT THREADS (15MM)			
B4B	1/4"	Bronze	\$ 34.75
B5B	5/16"	Bronze	\$ 34.75
B3B	3/8"	Bronze	\$ 34.75
1/2" ORIFICE, 1/2" NPT THREADS (15MM)			
FMWB	1/2" (15mm)	Bronze	\$ 39.84
5/8", 3/4" ORIFICE, 3/4" NPT THREADS			
FMW5B	5/8"	Bronze	\$ 41.47
FMW4B	3/4"	Bronze	\$ 41.47

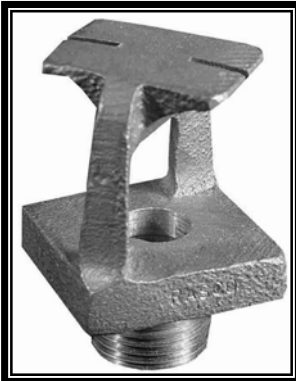

B & FM SPRAY NOZZLES

- Open Sprinklers
- Cornice Types
- See Bulletin 103

Part Number	Size	Finish	List Price
CORNICE TYPE MODEL FM — 1/2" ORIFICE, 1/2" NPT THREADS (15MM)			
FMCB	1/2"	Bronze	\$ 60.64
CORNICE TYPE MODEL FM — 5/8", 3/4" ORIFICE, 3/4" NPT THREADS			
FMC5B	5/8"	Bronze	\$ 69.04
FMC4B	3/4"	Bronze	\$ 69.04

WD	Requires Model D Sprinkler Wrench	\$	54.00
----	-----------------------------------	----	-------

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO allow 7-10 work days.



HV SPRAY NOZZLES

- High Velocity Nozzles
- With or Without Strainer
- Bulletin 105

Part Number				Discharge Angles	Finish	List Price
K=1.54	K=1.26	K=2.24	K = 1.82			
MODEL HV-A WITHOUT STRAINER						
6999994618	—	—	—	75°	Bronze	\$ 55.59
6999994619	—	—	—	75°	Chrome	\$ 58.96
—	6999994622	—	—	80°	Bronze	\$ 55.59
—	6999994623	—	—	80°	Chrome	\$ 58.96
—	—	6999994626	—	90°	Bronze	\$ 55.59
—	—	6999994627	—	90°	Chrome	\$ 58.96
—	—	—	6999994630	100°	Bronze	\$ 55.59
—	—	—	6999994631	100°	Chrome	\$ 58.96
MODEL HV-AS WITH STRAINER						
6999994620	—	—	—	75°	Bronze	\$ 57.25
6999994621	—	—	—	75°	Chrome	\$ 60.64
—	6999994624	—	—	80°	Bronze	\$ 57.25
—	6999994625	—	—	80°	Chrome	\$ 60.64
—	—	6999994628	—	90°	Bronze	\$ 57.25
—	—	6999994629	—	90°	Chrome	\$ 60.64
—	—	—	6999994632	100°	Bronze	\$ 57.25
—	—	—	6999994633	100°	Chrome	\$ 60.64



PLD

- Upright or Pendent
- Pilot Line Detector
- Bulletin 180

Part Number	Temperature		Finish	List Price
PILOT LINE DETECTOR				
PLD0B	135°F	57°C	Bronze	\$ 38.98
PLD0C	135°F	57°C	Chrome	\$ 41.62
PLD0W	135°F	57°C	White	\$ 43.67
PLD1B	155°F	68°C	Bronze	\$ 38.98
PLD1C	155°F	68°C	Chrome	\$ 41.62
PLD1W	155°F	68°C	White	\$ 43.67
PLD5B	175°F	79°C	Bronze	\$ 38.98
PLD5C	175°F	79°C	Chrome	\$ 41.62
PLD5W	175°F	79°C	White	\$ 43.67
PLD2B	200°F	93°C	Bronze	\$ 38.98
PLD2C	200°F	93°C	Chrome	\$ 41.62
PLD2W	200°F	93°C	White	\$ 43.67



Part Number					
R20	R30	R60	Angles	Finish	List Price
R20, R30, R60 1/2" NPT THREADS					
R2080B	R3080B	R6080B	80°	Bronze	\$ 68.66
R2080C	R3080C	R6080C	80°	Chrome	\$ 68.66
R20110B	R30110B	R60110B	110°	Bronze	\$ 68.66
R20110C	R30110C	R60110C	110°	Chrome	\$ 68.66
R20140B	R30140B	R60140B	140°	Bronze	\$ 68.66
R20140C	R30140C	R60140C	140°	Chrome	\$ 68.66

A SPRAY NOZZLE

- Spray Nozzles
- R20, R30, R60
- See Bulletin 106

Please refer to the latest sales bulletin for specific approval listings and available finishes. See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO allow 7-10 work days.