



**1 Sprinkler,
2 Applications!**

G4A CONCEALED

- Quick Response
- Concealed
- See Bulletin 154

G4A-300 CONCEALED

- Quick Response
- Concealed
- 300 PSI Rated
- See Bulletin 162

Please refer to the latest bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO allow 7-10 work days.

Part Number	Size	Temperature	Finish	List Price
SPRINKLER ONLY				
G4A1B	1/2" x 1/2" NPT (15mm)	165°F 74°C	Bronze	\$ 38.75
G4A13B	3/8" x 1/2" NPT	165°F 74°C	Bronze	\$ 48.07
G4A17B	7/16" x 1/2"	165°F 74°C	Bronze	\$ 48.07
G4A1M	1" Adjust Male	165°F 74°C	Bronze	\$ 103.55
G4A1F	1" Adjust Female	165°F 74°C	Bronze	\$ 103.55
G4A2B	1/2" x 1/2" NPT (15mm)	212°F 100°C	Bronze	\$ 38.75
G4A23B	3/8" x 1/2" NPT	212°F 100°C	Bronze	\$ 48.07
G4A27B	7/16" x 1/2"	212°F 100°C	Bronze	\$ 48.07
SPRINKLER ONLY — 300 PSI				
G4A1B3	1/2" x 1/2" NPT (15mm)	165°F 74°C	Bronze	\$ 40.65
G4A1M3	1" Adjust Male	165°F 74°C	Bronze	\$ 108.11
G4A1F3	1" Adjust Female	165°F 74°C	Bronze	\$ 108.11
REQUIRED COVERPLATES				
CG40B	—	135°F 57°C	Bronze	\$ 34.00
CG40C	—	135°F 57°C	Chrome	\$ 24.94
CG40W	—	135°F 57°C	White	\$ 24.94
CG40SP	—	135°F 57°C	Specialty	\$ 34.01

WG4 Requires Model G4 Wrench \$ 206.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.



F1FR CCP

- Push-On/Thread-off
- Concealed
- See Bulletins 143

F1FR-300/CCP

- Push-On/Thread-off
- 300 PSI Rated
- Quick Response
- Concealed
- See Bulletin 164

Part Number	Temperature	Finish	List Price
1/2" ORIFICE, 1/2" NPT THREADS (15MM)			
F1FRC0	135°F 57°C	Bronze	\$ 26.87
F1FRC1	155°F 68°C	Bronze	\$ 26.87
F1FRC5	175°F 79°C	Bronze	\$ 26.87
F1FRC2	200°F 93°C	Bronze	\$ 26.87
NEW! 1/2" ORIFICE, 1/2" NPT THREADS (15MM) — 300 PSI			
F1FRC03	135°F 57°C	Bronze	\$ 28.32
F1FRC13	155°F 68°C	Bronze	\$ 28.32
REQUIRED COVERPLATES (5/16")			
CCP05C76	135°F 57°C	Chrome	\$ 22.60
CCP05W76	135°F 57°C	White	\$ 22.60
CCP05SP76	135°F 57°C	Specialty	\$ 37.96
CCP15C76	165°F 74°C	Chrome	\$ 22.60
CCP15W76	165°F 74°C	White	\$ 22.60
CCP15SP76	165°F 74°C	Specialty	\$ 37.96
REQUIRED COVERPLATES (1/2"-15MM)			
CCP0C76	135°F 57°C	Chrome	\$ 22.60
CCP0W76	135°F 57°C	White	\$ 22.60
CCP0SP76	135°F 57°C	Specialty	\$ 37.96
CCP1C76	165°F 74°C	Chrome	\$ 22.60
CCP1W76	165°F 74°C	White	\$ 22.60
CCP1SP76	165°F 74°C	Specialty	\$ 37.96

WRC Requires Model RC1 Sprinkler Wrench \$ 207.00

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.



F4FR CONCEALED

- Quick Response
- Concealed
- See Bulletin 125


Part Number	Size	Temperature	Finish	List Price
SPRINKLER ONLY				
F4FR	1/2" x 1/2" NPT (15mm)	135°F 57°C	Bronze	\$ 68.77
F4FR3	3/8" x 1/2" NPT	135°F 57°C	Bronze	\$ 72.23
F4FR7	7/16" x 1/2" NPT	135°F 57°C	Bronze	\$ 72.23
F4FRM	1/2" Adjust. Male	135°F 57°C	Bronze	\$ 108.57
F4FRF	1/2" Adjust. Female	135°F 57°C	Bronze	\$ 108.57
REQUIRED COVERPLATES				
CG40B		135°F 57°C	Bronze	\$ 34.00
CG40C		135°F 57°C	Chrome	\$ 24.94
CG40W		135°F 57°C	White	\$ 24.94
CG40SP		135°F 57°C	Specialty	\$ 34.01

WG4 Requires Model G4 Sprinkler Wrench \$ 206.00

Please refer to the latest bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO allow 7-10 work days.

Notes:

For custom finishes, customer should provide paint sample.
Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.

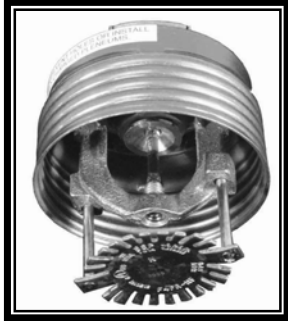

Part Number	Size	Temperature	Finish	List Price
F4FR-NF WITH COVERPLATE				
F4FRNFW	1/2" x 1/2" NPT (15mm)	135°F 57°C	White	\$ 133.75
F4FRNFC	1/2" x 1/2" NPT (15mm)	135°F 57°C	Chrome	\$ 133.75
F4FRNF1W	1/2" x 1/2" NPT (15mm)	155°F 68°C	White	\$ 133.75
F4FRNF1C	1/2" x 1/2" NPT (15mm)	155°F 68°C	Chrome	\$ 133.75

Non-Ferrous

WG4 Requires Model G4 Sprinkler Wrench \$ 206.00

Notes:

For custom finishes, customer should provide paint sample.

Allow at least 2-3 weeks. A set-up charge is required for all orders under 500 pieces. Consult factory for details.

F4FR-NF CONC

- Designed for:
 - MRI Rooms
 - Corrosive Environments
 - Swimming Areas
- Quick Response
- Concealed
- See Bulletin 002



XL Commercial

- Pendent/Horizontal Sidewall
- Quick Response
- No Exposed Heating Element!
- See Bulletin 145

Please refer to the latest bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape.
Items that are MTO allow 7-10 work days.

Part Number	Temperature	Finish	List Price
XL PENDENT			
XLQRPC	165°F 75°C	Chrome	\$ 97.89
XLQRPW	165°F 75°C	White	\$ 101.38
XL HSW			
XLQRHC	165°F 75°C	Chrome	\$ 122.37
XLQRHW	165°F 75°C	White	\$ 125.86
REQUIRED ESCUTCHEONS FOR MODEL XL			
ZXFPC	ZXCPC	Chrome	\$ 19.51
ZXFPW	ZXCPW	White	\$ 19.51
2-PIECE REQUIRED ESCUTCHEONS FOR MODEL XL			
	ZX2PC	Chrome	\$ 23.97
	ZX2PW	White	\$ 25.01
REQUIRED ESCUTCHEONS FOR MODEL XL (CONICAL)			
ZXCHC	165°F 75°C	Chrome	\$ 19.51
ZXCHW	165°F 75°C	White	\$ 19.51
2-PIECE REQUIRED ESCUTCHEONS FOR MODEL XL			
ZX2HC	165°F 75°C	Chrome	\$ 23.97
ZX2HW	165°F 75°C	White	\$ 25.01

WZXP	Requires Model ZX (Pendent) Sprinkler Wrench	\$	206.00
WZXH	Requires Model ZX (Horizontal) Sprinkler Wrench	\$	206.00

IMPORTANT NOTE:

- * The Model XL Quick Response Replaced our ZX Line as of 12/31/02
- * Sprinkler Components are Bright Chrome Only.
Link is painted silver or white.