



### F156 SREC

- K-Factor = 5.6 (80)
- Glass Bulb
- Thread Size = 1/2"
- See Bulletin 027




### F1 EC PENDENT

- Light Hazard (20' x 20')
- Extended Coverage  
- Glass Bulb
- See Bulletin 117

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO allow 7-10 work days.

Part Number	Temperature	Finish	List Price
<b>1/2" ORIFICE, 1/2" NPT THREADS (15MM)</b>			
F56ECP0B	135°F 57°C	Bronze	\$ 33.92
F56ECP0C	135°F 57°C	Chrome	\$ 33.92
F56ECP0W	135°F 57°C	White	\$ 36.58
F56ECP1B	155°F 68°C	Bronze	\$ 33.92
F56ECP1C	155°F 68°C	Chrome	\$ 33.92
F56ECP1W	155°F 68°C	White	\$ 36.58
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM)</b>			
FECP0LB	135°F 57°C	Bronze	\$ 37.01
FECP0LC	135°F 57°C	Chrome	\$ 37.01
FECP0LW	135°F 57°C	White	\$ 39.77
FECP1LB	155°F 68°C	Bronze	\$ 37.01
FECP1LC	155°F 68°C	Chrome	\$ 37.01
FECP1LW	155°F 68°C	White	\$ 39.77
<b>G/F1 ESCUTCHEONS</b>			
GF1B	1/2" (15mm)	Brass	\$ 14.24
GF1C	1/2" (15mm)	Chrome	\$ 7.05
GF1W	1/2" (15mm)	White	\$ 7.05
GF1LB	3/4" (20mm)	Brass	\$ 14.24
GF1LC	3/4" (20mm)	Chrome	\$ 7.05
GF1LW	3/4" (20mm)	White	\$ 7.05
GF1MB	10mm	Brass	\$ 12.92
GF1MC	10mm	Chrome	\$ 6.89
GF1MW	10mm	White	\$ 6.89

WD	Requires Model D Sprinkler Wrench	\$ 54.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 207.00

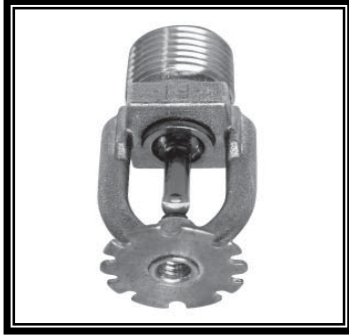

### F156-300 SREC

- K-Factor = 5.6 (80)
- Glass Bulb
- Thread Size = 1/2"
- See Bulletin 029



### F1-300 EC PENDENT

- Light Hazard (20' x 20')
- Extended Coverage  
- Glass Bulb
- See Bulletin 158

Please refer to the latest sales bulletin for specific approval listings and available finishes.

See our "Specialties Page" for special finish charges — including Teflon Tape.

Items that are MTO allow 7-10 work days.

Part Number	Temperature	Finish	List Price
<b>1/2" ORIFICE, 1/2" NPT THREADS (15MM) — 300 PSI</b>			
FEC3P0B3	135°F 57°C	Bronze	\$ 33.10
FEC3P0C3	135°F 57°C	Chrome	\$ 36.30
FEC3P0W3	135°F 57°C	White	\$ 39.04
FEC3P1B3	155°F 68°C	Bronze	\$ 33.10
FEC3P1C3	155°F 68°C	Chrome	\$ 36.30
FEC3P1W3	155°F 68°C	White	\$ 39.04
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM) — 300 PSI</b>			
FEC3P0LB3	135°F 57°C	Bronze	\$ 36.30
FEC3P0LC3	135°F 57°C	Chrome	\$ 39.46
FEC3P0LW3	135°F 57°C	White	\$ 42.24
FEC3P1LB3	155°F 68°C	Bronze	\$ 36.30
FEC3P1LC3	155°F 68°C	Chrome	\$ 39.46
FEC3P1LW3	155°F 68°C	White	\$ 42.24
<b>G/F1 ESCUTCHEONS</b>			
GF1B	1/2" (15mm)	Brass	\$ 14.24
GF1C	1/2" (15mm)	Chrome	\$ 7.05
GF1W	1/2" (15mm)	White	\$ 7.05
GF1LB	3/4" (20mm)	Brass	\$ 14.24
GF1LC	3/4" (20mm)	Chrome	\$ 7.05
GF1LW	3/4" (20mm)	White	\$ 7.05

WD	Requires Model D Sprinkler Wrench	\$ 54.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 207.00



**G-EC4 HSW**

- Horizontal Sidewall
- Extended Coverage (16' x 24')
- See Bulletin 112

Part Number	Temperature	Finish	List Price
<b>17/32" ORIFICE, 3/4" NPT THREADS (20MM)</b>			
GEC4LB	135°F 57°C	Bronze	\$ 45.28
GEC4LC	135°F 57°C	Chrome	\$ 49.20
<b>REQUIRED ESCUTCHEONS</b>			
GF1LB	3/4" (20mm)	Bronze	\$ 14.24
GF1LC	3/4" (20mm)	Chrome	\$ 7.05
GF1LW	3/4" (20mm)	White	\$ 7.05
GF1LSP	3/4" (20mm)	Specialty	\$ 12.40

WD	Requires Model D Sprinkler Wrench	\$ 54.00
WGFR	For Recessed Use Model GFR1 Wrench	\$ 207.00

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
See our "Specialties Page" for special finish charges — including Teflon Tape.  
Items that are MTO allow 7-10 work days.



Part Number	Temperature	Finish	List Price
<b>SPRAY UPRIGHT 3/4" NPT (20MM)</b>			
GFRUV1B	165°F 74°C	Bronze	\$ 79.33
GFRUV1C	165°F 74°C	Chrome	\$ 82.48
GFRUV2B	212°F 100°C	Bronze	\$ 79.33
GFRUV2C	212°F 100°C	Chrome	\$ 82.48

WH Requires Model H Sprinkler Wrench \$ 83.00

GFR VELO-ECOH

- Extended Coverage  
Ordinary Hazard Upright
- Up to 400 sq. ft
- See Bulletin 165



Part Number	Temperature	Finish	List Price
<b>SPRAY PENDENT 20' X 20'</b>			
GFRPV1B	165°F 74°C	Bronze	\$ 59.01
GFRPV1C	165°F 74°C	Chrome	\$ 61.40
GFRPV1W	165°F 74°C	White	\$ 64.02
GFRPV2B	212°F 100°C	Bronze	\$ 59.01
GFRPV2C	212°F 100°C	Chrome	\$ 61.40
GFRPV2W	212°F 100°C	White	\$ 64.02


GFR VELO ECOH

- 14.0 K Factor, 3/4" NPT
- See Bulletin 160

\*Recessing available.

WH Requires Model H Sprinkler Wrench \$ 83.00  
 WXLO Requires Model XLO Sprinkler Wrench \$ 109.00  
 for Recessing

Please refer to the latest sales bulletin for specific approval listings and available finishes.  
 See our "Specialties Page" for special finish charges — including Teflon Tape.  
 Items that are MTO allow 7-10 work days.

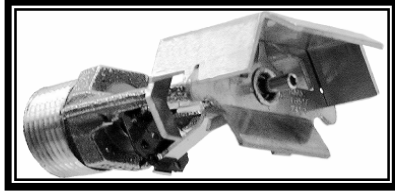

## MBEC-14 HSW

- Standard Response
- Extended Coverage
- HSW
- See Bulletin 169

*Horizontal  
Sidewall  
Sprinklers for  
Metal Building  
Applications!*

Part Number	Temperature	Finish	List Price
<b>MBEC-14</b>			
MB1B	165°F 74°C	Bronze	\$ 62.42
MB1C	165°F 74°C	Chrome	\$ 71.60
MB1W	165°F 74°C	White	\$ 71.60
MB2B	212°F 100°C	Bronze	\$ 62.42
MB2C	212°F 100°C	Chrome	\$ 71.60
MB2W	212°F 100°C	White	\$ 71.60

WH Requires Model H Sprinkler Wrench \$ 83.00

### FEATURES:

1. Designed to be installed on piping that is supported by the primary roof beams and not the purlins.
2. Provides Extended Coverage Ordinary & Extra Hazard protection.
3. Very extra large orifice of nominal K=14 permits low pressures.

### IMPORTANT NOTE:

Patent Pending