




Model B-1 Accelerator

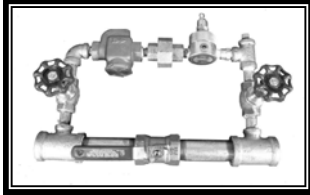

A-2 Automatic Air Pressure Maintenance Device

Part Name	Part Number	List Price
ACCELERATOR		
B1 Accelerator	AE	\$ 1,514.00
B2 Accelerator Trim	ACT	\$ 622.00
Replacement Parts Kit - B	BRPK	\$ 514.00
Replacement Parts Kit - B1	B1RPK	\$ 514.00
DRY VALVE TRIM ACCESSORIES		
Fill Line- Model A (2-1/2")	25FLTG	\$ 197.00
Fill Line- Model D (4 & 6")	4FLTG	\$ 197.00
Priming Chamber	PCG	\$ 344.00
AIR MAINTENANCE DEVICE		
A-2 Owner's Air	AMDAG	\$ 950.00
B-1 Individual Compressor	AMDBG	\$ 1,079.00
C Supertrol Systems	AMDCG	\$ 1,425.00
PRESSURE ALARM SWITCHES		
EPS10-1 Alarm, Single SPDT (System Sensor)- Set 4-8PSI	EPS10-1	\$ 212.50
EPS10-2 Alarm, Double SPDT (System Sensor)- Set 4-8PSI	EPS10-2	\$ 246.25
EPS40-1 Supervisory, Single SPDT- Adj 10-100PSI	EPS40-1	\$ 212.50
EPS40-2 High/Low Supervisory Double SPDT- Adj 10-100PSI	EPS40-2	\$ 246.25
VALVE SEAT WRENCHES		
2-1/2" Model A Dry Pipe Valve	W4DPV	\$ 148.00
4" Model D Dry Pipe Valve	W4DPV	\$ 148.00
6" Model D Dry Pipe Valve	W6DPV	\$ 162.00

VALVES ACCESSORIES

- See Bulletins 250, 251, 320, 322



Part Name	Part Number	List Price
DRY SYSTEM AUXILIARY CONDENSATE DRAIN		
ACD Dry System Auxiliary Condensate Drain w- Sight Glass	ACD	\$ 525.00

Model ACD Dry System Auxiliary Condensate Drain or "Drum Drip Drain" is used in Dry Pipe and Preaction Sprinkler Systems, which meet NFPA 13 (2007) Installation Requirements section 8.16.2.5.3.4.

Features:

1. Sight Glass included
2. Eliminates field assembly
3. Ball Valves - quick operation
4. No assembly required
5. 1" NPT Union end connection for ease of installation
6. 1" Plug included

ACD Dry System Auxiliary Condensate Drain with Sight Glass

- See Bulletin 441



AIR COMPRESSORS

- See Bulletin 275
& Gast F-30

Part Name	Part Number	List Price
AIR COMPRESSOR — BARE		
1/6 HP, 115-60-1, Gast 1LAA-10-M100X	16A	\$ 952.11
1/4 HP, 115-60-1, Gast 2LAF-10-M200X	14A	\$ 1,100.87
1/3 HP, 115-60-1, Gast 3LBA-33-M300X	13A	\$ 1,316.99
1/2 HP, 115-60-1, Gast 4LCB-10-M450X	12A	\$ 1,715.12
3/4 HP, 115/230-60-1, Gast 5LCA-10-M550X	34A	\$ 1,783.17
3/4 HP, 230/460-60-3, Gast 5LCA-10-M553	34A3	\$ 2,210.60
1 HP, 115/230-60-1, Gast 6LCF-10-M616X	1A	\$ 2,276.35
1-1/2 HP, 115/230-60-1, Gast 7LDE-10-M700X	112A	\$ 3,797.44
2 HP, 115/230-60-1, Gast 8LDF-10-M850X	2A	\$ 4,492.89
WITH CHECK VALVE AND PRESSURE SWITCH		
1/6 HP, 115-60-1, Gast 1LAA-32-M100X	16PA	\$ 1,495.19
1/4 HP, 115-60-1, Gast 2LAF-12-M200X	14PA	\$ 1,523.32
1/3 HP, 115-60-1, Gast 3LBA-32-M300X	13PA	\$ 1,769.49
1/2 HP, 115-60-1, Gast 4LCB-21-M450X	12PA	\$ 2,109.39
3/4 HP, 115/230-60-1, Gast 5LCA-22-M550X	34PA	\$ 2,284.80
1 HP, 115/230-60-1, Gast 6LCF-13-M616X	1PA	\$ 2,727.03
1-1/2 HP, 115/230-60-1, Gast 7LDE-16-M750X	112PA	\$ 4,173.28
2 HP, 115/230-60-1, Gast 8LDF-16-M850X	2PA	\$ 5,106.68
AIR COMPRESSORS -- TANK MOUNTED		
1/6 HP, 115-60-1, Gast 1LAA-11T-M100X, 2 GAL	16TA	\$ 2,212.51
1/4 HP, 115-60-1, Gast 2LAF-11T-M200X, 12 GAL	14TA	\$ 2,913.44
1/3 HP, 115-60-1, Gast 3LBA-11T-M300X 12 GAL	13TA	\$ 3,310.78
1/2 HP, 115-60-1, Gast 4LCB-11T-M450X, 20 GAL	12TA	\$ 3,623.10
3/4 HP, 115/230-60-1, Gast 5LCA-11T-M550X, 20 GAL	34TA	\$ 3,737.41
1 HP, 115/230-60-1, Gast 6LCF-11T-M616X, 30 GAL	1TA	\$ 4,542.99
1-1/2 HP, 115/230-60-1, Gast 7LDE-11T-M750X, 30 GAL	112TA	\$ 6,784.14
2 HP, 115/230-60-1, Gast 8LDF-11TC-M850X, 30GAL	2TA	\$ 9,179.95
AIR COMPRESSORS -- REPAIR KITS *		
1/3 HP, Repair Kit	6888000010	\$ 340.00
3/4 HP, Repair Kit	6888000020	\$ 303.41
1-1/2 HP, Repair Kit	6888000030	\$ 564.80
Riser Mounting Brackets	6999990969	\$ 136.00

*Repair Kit Contains: Gaskets, Piston, Seals, Piston Rings, In/Out Valve Plates, Manifold Seals and Felts (for Filters)

VALVE ACCESSORIES

Part Name	Part Number	List Price
PRESSURE GAUGES		
Water	WATER	\$ 69.20
Air	AIR	\$ 73.98
Air (0-60 oz/in ²)	98248002	\$ 262.07
INSPECTORS TEST CONNECTIONS		
Sight Test Type (Model B)	ISC	\$ 286.00
Blind Test Type (Model A)	IBC	\$ 96.00
AUTOMATIC BALL DRIPS		
1/2" NPT (Female)	78653500	\$ 165.80
3/4" NPT (Female)	78653700	\$ 189.40
MECHANICAL BALL DRIPS		
1/2" NPT (Female)	78653100	\$ 295.90
STRAINER		
3/4" NPT (Female)	78650200	\$ 173.90
MISCELLANEOUS		
Model C Sight Drain 2" NPT (Female)	6863000000	\$ 310.00
Model B Drum Drip Only 3/4" NPT (Female)	71010448	\$ 190.00
Model A Fill Cup 1/2" NPT (Female)	75000050	\$ 89.70
Model A Fill Cup 3/4" NPT (Female)	75000075	\$ 101.50
Model A Control Valve Seal Only	6869800000	\$ 25.00
SIGNS—MODEL A		
Valve Control Sign	6892011000	\$ 12.80
SIGNS—MODEL B		
Inspector Test Sign	ITS	\$ 2.50
Open Sprinkler Control Sign	OSCS	\$ 2.70
Open Sprinkler Drain Sign	OSDS	\$ 2.70
Test Valve Sign	TVS	\$ 2.70
Water Motor Line Sign	WMLS	\$ 2.70
Auxiliary Drain Sign	ADS	\$ 2.50
Main Drain Sign	MDS	\$ 2.50
Drain Sign	DS	\$ 2.40
Alarm Test Sign	ATS	\$ 2.70
SIGNS—MODEL C		
Cold Weather Sign	CWS	\$ 10.70
SIGNS—MODEL D		
Fire Alarm Sign	FAS	\$ 12.80
SIGNS—MODEL E		
Hydraulically Calculated System	HCS	\$ 7.10

Please refer to the latest sales bulletin for specific approval listings and available finishes.
See our "Specialties Page" for special finish charges — including Teflon Tape. Items that are MTO allow 7-10 work days.



Part Name	Size	Part Num	List Price
MULTI-PURPOSE RISER			
Model MP	1" (30mm)	1MP	\$ 749.00
RISER ACCESSORIES			
Optional Support Bracket Kit		RRB	\$ 67.00

- 1" Residential Riser for providing water flow alarm on Multipurpose Residential Fire Sprinkler Systems
- cULus Listed

Multipurpose) Residential

Riser

- See Bulletin 414

* For our Multipurpose Low Lead Residential Riser, please see S-105,



Residential Riser

- See Bulletin 425

Part Name	Size	Part Num	List Price
RISER ASSEMBLIES			
Base Unit	1" (30mm)	1RR	\$ 749.00
Base Unit and Pressure Relief Valve Trim	1" (30mm)	1RRT	\$ 1,085.00
Base Unit with 1 x 1/2" Test & Drain	1" (30mm)	1RRD	\$ 1,176.00
Base Unit	1-1/2" (40mm)	15RR	\$ 749.00
Base Unit and Pressure Relief Valve Trim	1-1/2" (40mm)	15RRT	\$ 1,085.00
Base Unit with 1 x 1/2" Test & Drain	1-1/2" (40mm)	15RRD	\$ 1,176.00
Base Unit	2" (50mm)	2RR	\$ 837.00
Base Unit and Pressure Relief Valve Trim	2" (50mm)	2RRT	\$ 1,173.00
Base Unit with 1 x 1/2" Test & Drain	2" (50mm)	2RRD	\$ 1,264.00
RISER ASSEMBLIES - CANADIAN VERSION			
Base Unit - Canada	1" (30mm)	1RRC	\$ 749.00
Base Unit & Pressure Relief Valve Trim - Canada	1" (30mm)	1RRTC	\$ 1,087.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1" (30mm)	1RRDC	\$ 1,176.00
Base Unit - Canada	1-1/2" (40mm)	15RRC	\$ 749.00
Base Unit & Pressure Relief Valve Trim - Canada	1-1/2" (40mm)	15RRTC	\$ 1,087.00
Base Unit with 1 x 1/2" Test & Drain - Canada	1-1/2" (40mm)	15RRDC	\$ 1,176.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRC	\$ 837.00
Base Unit & Pressure Relief Valve Trim - Canada	2" (50mm)	2RRTC	\$ 1,173.00
Base Unit with 1 x 1/2" Test & Drain - Canada	2" (50mm)	2RRDC	\$ 1,264.00
RISER ACCESSORIES			
Pressure Relief Valve Trim (good for all sizes)		15PRTCR	\$ 177.00
Optional Support Bracket Kit		RRB	\$ 67.00


Note: Other combinations available upon request.



Model CR Commercial Riser

- For Commercial Applications
- See Bulletin 617

Part Name	Size	Part Number	List Price
COMMERCIAL RISER			
Model CR Commercial Riser - Threaded	1-1/2" (40mm)	15CR	\$ 822.22
Model CR Commercial Riser - Threaded	2" (50mm)	2CR	\$ 822.22
Model CR Commercial Riser - Grooved	2" (50mm)	2CRG	\$ 822.22
Model CR Commercial Riser - Grooved	2-1/2" (65mm)	25CRG	\$ 916.43
Model CR Commercial Riser - Grooved	3" (80mm)	3CRG	\$ 959.24
Model CR Commercial Riser - Grooved	4" (100mm)	4CRG	\$ 1,164.80
Model CR Commercial Riser - Grooved	6" (150mm)	6CRG	\$ 1,284.71
Model CR Commercial Riser - Grooved	8" (200mm)	8CRG	\$ 1,421.73

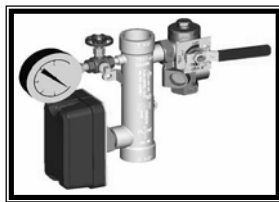

Model CR Commercial Riser with Test & Drain

- For Commercial Applications
- See Bulletin 617

Part Name	Size	Part Number	List Price
CR COMMERCIAL RISER WITH TEST & DRAIN			
Model CR Commercial Riser w- Test&Drain - Threaded	1-1/2" (40mm)	15FC	\$ 1,113.41
Model CR Commercial Riser w- Test&Drain - Threaded	2" (50mm)	2FC	\$ 1,130.55
Model CR Commercial Riser w- Test&Drain - Grooved	2" (50mm)	2FCG	\$ 1,267.58
Model CR Commercial Riser w- Test&Drain - Grooved	2-1/2" (65mm)	25FC	\$ 1,336.09
Model CR Commercial Riser w- Test&Drain - Grooved	3" (80mm)	3FC	\$ 1,353.22
Model CR Commercial Riser w- Test&Drain - Grooved	4" (100mm)	4FC	\$ 1,627.30
Model CR Commercial Riser w- Test&Drain - Grooved	6" (150mm)	6FC	\$ 1,678.68
Model CR Commercial Riser w- Test&Drain - Grooved	8" (200mm)	8FC	\$ 1,884.25
PRESSURE RELIEF KITS			
Pressure Relief Trim - NPT	1-1/2" (40mm) - 2" (50mm)	15PRTCR	\$ 177.00
Pressure Relief Trim - Grooved End	2" (50mm)	2PRTCRG	\$ 177.00
Pressure Relief Trim - Grooved End	2-1/2" (65mm) - 3" (80mm)	25PRTCRG	\$ 177.00
Pressure Relief Trim - Grooved End	4" (150mm) - 8" (200mm)	4PRTCRG	\$ 311.00