

Grooved x Grooved Alarm Valves




- > Available sizes: 4", 6", 165mm & 8"
- > 300 psi rating
- > cULus Listed, FM Approved, LPCB Approved
- > Simplified, galvanized trim in segmented or loose versions
- > Optional TestANDrain® trim. May eliminate the need for a separate inspector's test connections
- > Optional Pressure Relief Trim
- > Refer to **Bulletin 410** for more information

E-3 Alarm Valve
(without TestANDrain®)

Are your fire sprinkler systems getting larger and more complicated?

Use the alarm valve that is smaller and simplified

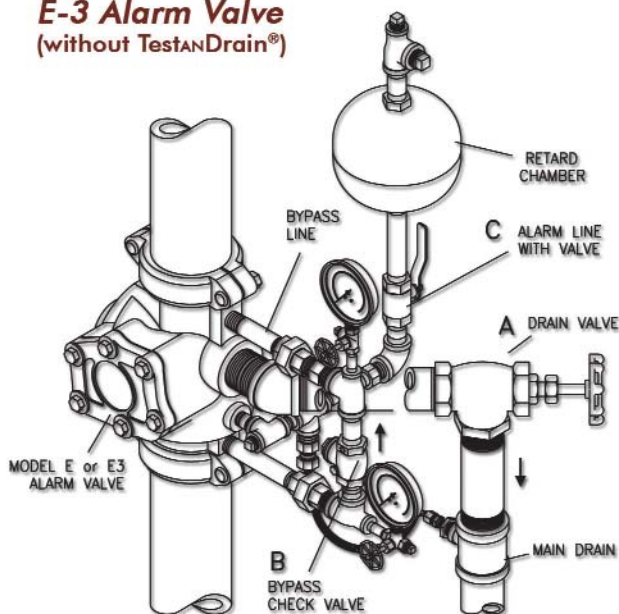

E-3 Alarm Trim
(with TestANDrain®)

- > Simplified, galvanized trim in segmented or loose versions
- > Only 7 small segments make-up the entire simplified trim package
- > Extremely compact, takes up less space
- > Variable and constant pressure closed trim with an open trim option
- > Testing the valve's alarm devices will exercise the valve clapper
- > Optional TestANDrain® trim. May eliminate the need for a separate inspector's test connection if approved by AHJ
- > Optional pressure relief trim
- > *Available sizes: 4", 6", 165mm & 8"
- > cULus Listed, FM Approved, LPCB Approved
- > Refer to Bulletin 410 for more information
- *not available in 2.5" or 3"