

Maximize Storage. Minimize Wasted Space.

cULus Listed ESFR Sprinklers for Roof Deck Heights up to 48 ft.




Model P25

- 40 ft. tall storage
- 5 ft. min. aisle width
- 50 psi operating pressure
- Single- and double-row open frame racks



Model N28T6

- 43 ft. tall storage
- 4 ft. min. aisle width
- 35 psi operating pressure
- Single-, double-, and multiple-row open frame racks

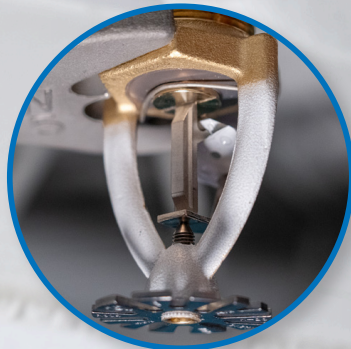

Model N28T3

- 43 ft. tall storage
- 4 ft. min. aisle width
- 35 psi operating pressure
- Single-, double-, and multiple-row open frame racks
- 3 in. transverse flue spaces in single- and double-row open frame racks



- See Reliable Technical Bulletins 070 and 082 for complete details and limitations.
- Reliable has developed, and ASTM International has published, an Environmental Product Declaration (EPD) for the Model P25, N28T6 and N28T3 sprinklers.

Reliable[®]

reliablesprinkler.com



SEE
OUR
48'
LINEUP