


## Brass Ball Valve

## R0036A

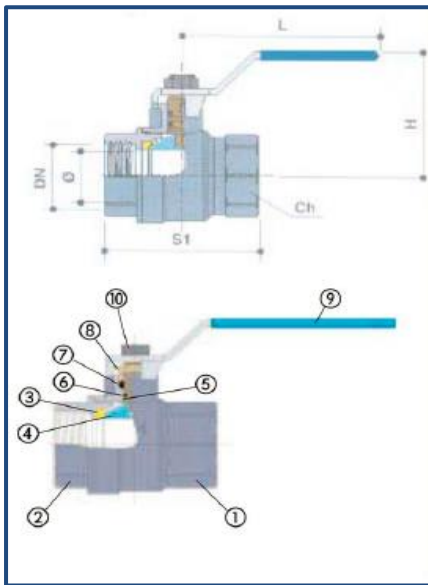

### Technical Features

Screwed BSP Parallel  
PTFE East  
Anti Blow Out Stem  
Full Bore

### Pressure & Temperature

Technical Data	1/4" - 1"	1 1/4" - 1"
Max Pressure	32 bar	25 bar
Working Temp.	-10°C to 110°C	-10°C to 110°C

### Material List

No.	Description	Material	Treatment
1	Body	Brass	Nickel plated
2	Body End	Brass	Nickel plated
3	Seat	PTFE	
4	Ball	Brass	Chrome plated
5	Stem	Brass	
6	O-Ring	NBR	
7	Seal	PTFE	
8	Packing Nut	Brass	
9	Handle	Steel	PVC-Plastic plated
10	Nut	Steel	Zinc plated

### Dimensions

DN	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"
Ø	10.5	10.5	15	20	25	32	40	50
S1	41.5	43.5	48	58	69	80	91	108
H	39.5	39.5	42	44	57	61	72	77
L	80	80	90	90	105	105	150	150
Ch	17.5	20.5	25	31	38	47	54	66
Kgs	0.12	0.12	0.19	0.28	0.41	0.60	0.97	1.43

### Ordering Information

Description	Size	Part Number
Brass Ball Valve Female Thread	15mm / 1/2"	7U99001989
Brass Ball Valve Female Thread	20mm / 3/4"	7U99001990
Brass Ball Valve Female Thread	25mm / 1"	7U99001991
Brass Ball Valve Female Thread	32mm / 1 1/4"	7U99001992
Brass Ball Valve Female Thread	40mm / 1 1/2"	7U99001993
Brass Ball Valve Female Thread	50mm / 2"	7U99001994