

N28 ESFR

Specific Application ESFR Pendent
Sprinklers, 175 psi (12 bar) rated

Optimize Storage Space


Space-Efficient N28 ESFR Sprinkler Features:

- cULus Listed
- Protection of storage under ceiling heights up to 48 ft (14.6 m)
- 4 ft (1.2 m) aisles and multiple-row racks in accordance with the 2022 edition of NFPA 13
- Model N28T3 allows transverse flue spaces as small as 3 in (75 mm)
- Durable fusible alloy solder link requires no shipping protector

Model	Nominal K-factor	Min. Transverse Flue Space Width
N28T3	28.0 (400)	3 in (75 mm)
N28T6		6 in (150 mm)



Maximize Your Warehouse Space with Reliable N28 ESFR Sprinklers

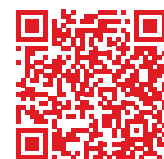

For Specific
Application
Listings, see
Bulletin 082.

Reliable[®]

reliablesprinkler.com/N28

