
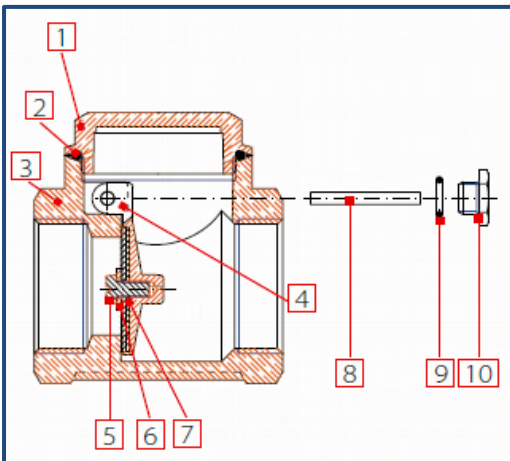


Swing Check Valve

R0034A

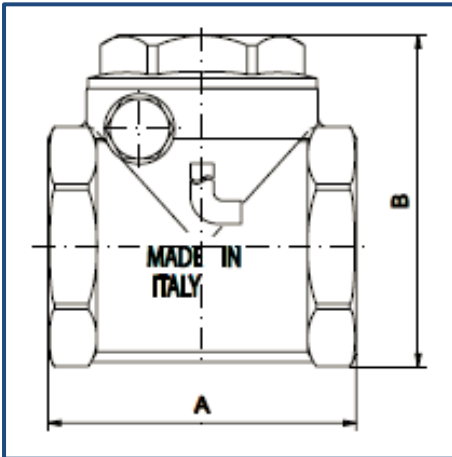

Technical Features

Body in brass.

O-ring for hexagonal plug in NBR.

Washer of the size plug in NBR.

Plate in brass.

Min and max working temperatures: - 0°C, 90°C.

Threads: ISO228 (equivalent to DIN EN ISO 228 and BE EN ISO 228).

Sizes

Size	¾"	1"	1¼"
A (mm)	52	62	72
B (mm)	59.5	68	77
Working Pressure (bar)	16	12	10

Material Specification

No.	Description	Material
1	End Adapter	Brass CW617N
2	O-Ring	NBR
3	Body	Hot pressed brass CW617N
4	Batten	Hot pressed brass CW617N
5	Screw	Brass CW614N
6	Flat Washer	Brass UNI EN 1652
7	Washer	NBR
8	Pin	Brass CW614N
9	O-Ring	NBR
10	Plug	Brass CW614N

Ordering Information

Description	Size	Part Number
Brass Swing Check Valve	20mm / ¾"	7U99001980
Brass Swing Check Valve	25mm / 1"	7U99001981
Brass Swing Check Valve	32mm / 1¼"	7U99001982