



G5-80

- K-Factor = 8.0 (115)
- **SIN RA3412**
- See Bulletin 034

G5-56

- K-Factor = 5.6 (80)
- **SIN RA3415**
- See Bulletin 034

G5-42

- K-Factor = 4.2 (60)
- **SIN RA3413**
- See Bulletin 034

G5-28

- K-Factor = 2.8 (40)
- **SIN RA3411**
- See Bulletin 034



**New - Perforated
 Cover Plate**

Part Number	Short Code	Temperature	Finish	List Price
MODEL G5-80 CONCEALED K8.0 (115) THREADS 3/4" (20MM) RA3412				
1916173498	G5801B	165°F 74°C	Bronze	\$ 65.02
1921173498	G5802B	212°F 100°C	Bronze	\$ 65.02
MODEL G5-80 CONCEALED K8.0 (115) THREADS 3/4" (20MM) RA3412 FM ONLY				
1916173497	G5801BFM	165°F 74°C	Bronze	\$ 68.58
1921173497	G5802BFM	212°F 100°C	Bronze	\$ 68.58
MODEL G5-80 CONCEALED K8.0 (115) THREADS BSPT 3/4" (20MM) RA3412 FM ONLY				
1916173494	G5801MFM	165°F 74°C	Bronze	\$ 68.58
1921173494	G5802MFM	212°F 100°C	Bronze	\$ 68.58
MODEL G5-56 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA3415				
1916173299	G51B	165°F 74°C	Bronze	\$ 52.43
1921173299	G52B	212°F 100°C	Bronze	\$ 52.43
MODEL G5-42 CONCEALED K4.2 (60) THREADS 1/2" (15MM) RA3413				
1916172899	G5421B	165°F 74°C	Bronze	\$ 65.02
1921172899	G5422B	212°F 100°C	Bronze	\$ 65.02
MODEL G5-28 CONCEALED K2.8 (40) THREADS 1/2" (15MM) RA3411				
1916172499	G5281B	165°F 74°C	Bronze	\$ 65.02
1921172499	G5282B	212°F 100°C	Bronze	\$ 65.02
MODEL G4 PLAIN COVERPLATES				
6887011321	CG40C	135°F 57°C	Chrome	\$ 33.75
6887011372	CG40W	135°F 57°C	White	\$ 33.75
6887011311	CG40B	135°F 57°C	Bronze	\$ 46.41
6887011374	CG40OW	135°F 57°C	Off-White	\$ 45.91
6887011390	CG40SP	135°F 57°C	Specialty	\$ 46.03
6887011316	CG40FB	135°F 57°C	Black Painted	\$ 45.97
6887011367	CG40BP	135°F 57°C	Black Plated	\$ 56.18
6887011305	CG40BB	135°F 57°C	Bright Brass	\$ 56.18
6887011323	CG40CD	135°F 57°C	Satin Chrome	\$ 56.18
6887011310	CG40SS	135°F 57°C	Stainless Steel	\$ 56.18
6887011621	CG41C	165°F 74°C	Chrome	\$ 33.75
6887011672	CG41W	165°F 74°C	White	\$ 33.75
6887011611	CG41B	165°F 74°C	Bronze	\$ 46.41
6887011674	CG41OW	165°F 74°C	Off-White	\$ 45.91
6887011690	CG41SP	165°F 74°C	Specialty	\$ 46.03
6887011616	CG41FB	165°F 74°C	Black Painted	\$ 45.91
6887011667	CG41BP	165°F 74°C	Black Plated	\$ 56.18
6887011605	CG41BB	165°F 74°C	Bright Brass	\$ 56.18
6887011623	CG41CD	165°F 74°C	Satin Chrome	\$ 56.18
6887011610	CG41SS	165°F 74°C	Stainless Steel	\$ 56.18
MODEL G4 PERFORATED COVERPLATES				
6887181321	CG40CP	135°F 57°C	Chrome	\$ 36.45
6887181372	CG40WP	135°F 57°C	White	\$ 36.45
6887181390	CG40SPP	135°F 57°C	Specialty	\$ 48.72
6887181621	CG41CP	165°F 74°C	Chrome	\$ 36.45
6887181672	CG41WP	165°F 74°C	White	\$ 36.45
6887181690	CG41SPP	165°F 74°C	Specialty	\$ 48.72
IF REPLACING INSTALLED G4A SPRINKLERS, NEED REQUIRED ADAPTER				
6999991900	EXT55			\$ 3.84

6880170020 WFC Requires Model FC Wrench \$ 287.62

Notes:

Sprinkler and coverplates sold and packaged separately. Standard Spray QR - Quick Response, Decorative Sprinklers



G6-56 HSW QR

- K-Factor = 5.6 (80)
- **SIN RA5035**
- See Bulletin 050

Part Number	Short Code	Temperature		Finish	List Price
MODEL G6-56 HSW CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA5035					
2116173299	G6H1B	165°F	74°C	Bronze	\$ 105.18
MODEL G6 PLAIN COVERPLATES					
6887211311	CG60B	135°F	57°C	Bronze	\$ 47.08
6887211321	CG60C	135°F	57°C	Chrome	\$ 33.75
6887211372	CG60W	135°F	57°C	White	\$ 33.75
6887211390	CG60SP	135°F	57°C	Specialty	\$ 49.09
MODEL G6 PERFORATED COVERPLATES					
6887221311	CG60BP	135°F	57°C	Bronze	\$ 47.08
6887221321	CG60CP	135°F	57°C	Chrome	\$ 33.75
6887221372	CG60WP	135°F	57°C	White	\$ 33.75
6887221390	CG60SPP	135°F	57°C	Specialty	\$ 49.09

6880101010	WG6	Requires Model G6 Sprinkler Wrench	\$ 287.62
------------	-----	------------------------------------	-----------

Notes:

Sprinkler and coverplates sold and packaged separately



G5-80 QR "Sealing" Concealed

- K-Factor = 8.0 (115)
- **SIN RA3412**
- See Bulletin 034

G5-56 QR "Sealing" Concealed

- K-Factor = 5.6 (80)
- **SIN RA3415**
- See Bulletin 034

G5-42 QR "Sealing" Concealed

- K-Factor = 4.2(60)
- **SIN RA3413**
- See Bulletin 034


G5-28 QR "Sealing" Concealed

- K-Factor = 2.8 (40)
- **SIN RA3411**
- See Bulletin 034

Part Number	Short Code	Temperature		Finish	List Price
MODEL G5-80 CONCEALED K8.0 (115) THREADS 3/4" (20MM) RA3412					
1916173498	G5801B	165°F	74°C	Bronze	\$ 65.02
1921173498	G5802B	212°F	100°C	Bronze	\$ 65.02
MODEL G5-56 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA3415					
1916173299	G51B	165°F	74°C	Bronze	\$ 52.43
1921173299	G52B	212°F	100°C	Bronze	\$ 52.43
MODEL G5-42 CONCEALED K4.2 (60) THREADS 7/16" (10MM) RA3413					
1916172899	G5421B	165°F	74°C	Bronze	\$ 65.02
1921172899	G5422B	212°F	100°C	Bronze	\$ 65.02
MODEL G5-28 CONCEALED K2.8 (40) THREADS 3/8" (10MM) RA3411					
1916172499	G5281B	165°F	74°C	Bronze	\$ 65.02
1921172499	G5282B	212°F	100°C	Bronze	\$ 65.02
MODEL G5 SEALING CONCEALED COVERPLATE					
6887201372	CG5S0W	135°F	57°C	White	\$ 86.33
6887201672	CG5S1W	165°F	74°C	White	\$ 86.33
6887201310	CG5S0SS	135°F	57°C	Stainless Steel	\$ 89.88
6887201610	CG5S1SS	165°F	74°C	Stainless Steel	\$ 89.88

6880170020 WFC Requires Model FC Wrench \$ 287.62

Notes:
 Sprinkler and coverplates sold separately

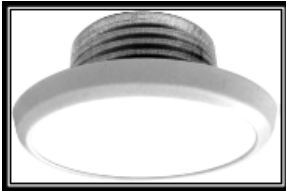

G5-56 300 QR
"Sealing" Concealed

- K-Factor = 5.6 (80)
- **SIN RA4014**
- See Bulletin 034

Part Number	Short Code	Temperature		Finish	List Price
MODEL G5-56 300 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA4014					
2016173299	G51B3	165°F	74°C	Bronze	\$ 55.41
MODEL G5 SEALING CONCEALED COVERPLATE REQUIRED					
6887201372	CG5S0W	135°F	57°C	White	\$ 86.33
6887201672	CG5S1W	165°F	74°C	White	\$ 86.33
6887201310	CG5S0SS	135°F	57°C	Stainless Steel	\$ 89.88
6887201610	CG5S1SS	165°F	74°C	Stainless Steel	\$ 89.88
6880170020	WFC	Requires Model FC Wrench			\$ 287.62



G5-56 300 Concealer

- K-Factor = 5.6 (80)
- **SIN RA4014**
- See Bulletin 034



Perforated Cover Plate

Part Number	Short Code	Temperature		Finish	List Price
MODEL G5-56 300 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA4014					
2016173299	G51B3	165°F	74°C	Bronze	\$ 55.41
MODEL G4 PLAIN COVERPLATES					
6887011321	CG40C	135°F	57°C	Chrome	\$ 33.75
6887011372	CG40W	135°F	57°C	White	\$ 33.75
6887011311	CG40B	135°F	57°C	Bronze	\$ 46.41
6887011374	CG40OW	135°F	57°C	Off-White	\$ 45.91
6887011390	CG40SP	135°F	57°C	Specialty	\$ 46.03
6887011316	CG40FB	135°F	57°C	Black Painted	\$ 45.97
6887011367	CG40BP	135°F	57°C	Black Plated	\$ 56.18
6887011305	CG40BB	135°F	57°C	Bright Brass	\$ 56.18
6887011323	CG40CD	135°F	57°C	Satin Chrome	\$ 56.18
6887011310	CG40SS	135°F	57°C	Stainless Steel	\$ 56.18
6887011621	CG41C	165°F	74°C	Chrome	\$ 33.75
6887011672	CG41W	165°F	74°C	White	\$ 33.75
6887011611	CG41B	165°F	74°C	Bronze	\$ 46.41
6887011674	CG41OW	165°F	74°C	Off-White	\$ 45.91
6887011690	CG41SP	165°F	74°C	Specialty	\$ 46.03
6887011616	CG41FB	165°F	74°C	Black Painted	\$ 45.91
6887011667	CG41BP	165°F	74°C	Black Plated	\$ 56.18
6887011605	CG41BB	165°F	74°C	Bright Brass	\$ 56.18
6887011623	CG41CD	165°F	74°C	Satin Chrome	\$ 56.18
6887011610	CG41SS	165°F	74°C	Stainless Steel	\$ 56.18
MODEL G4 PERFORATED COVERPLATES					
6887181390	CG40SPP	135°F	57°C	Specialty	\$ 48.72
6887181621	CG41CP	165°F	74°C	Chrome	\$ 36.45
6887181672	CG41WP	165°F	74°C	White	\$ 36.45
6887181690	CG41SPP	165°F	74°C	Specialty	\$ 48.72

6880170020	WFC	Requires Model FC Wrench	\$ 287.62
------------	-----	--------------------------	-----------



F1FR56 CCP

- K-Factor = 5.6 (80)
- **SIN RA1414**
- See Bulletin 014

F1FR56-300/CCP

- K-Factor = 5.6 (80)
- **SIN RA2614**
- See Bulletin 026

Part Number	Short Code	Temperature		Finish	List Price
MODEL F1FR56 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA1414					
BV13173299	F1FR56C0	135°F	57°C	Bronze	\$ 36.69
BV15173299	F1FR56C1	155°F	68°C	Bronze	\$ 36.69
BV17173299	F1FR56C5	175°F	79°C	Bronze	\$ 36.69
BV20173299	F1FR56C2	200°F	93°C	Bronze	\$ 36.69
MODEL F1FR56-300 CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA2614					
BP131732R9	F1FR56C03	135°F	57°C	Bronze	\$ 38.68
BP151732R9	F1FR56C13	155°F	68°C	Bronze	\$ 38.68
MODEL CCP COVERPLATES (5/16" ADJ)					
6887171321	CCP05C76	135°F	57°C	Chrome	\$ 78.48
6887171318	CCP05W76	135°F	57°C	White	\$ 30.58
6887171390	CCP05SP76	135°F	57°C	Specialty	\$ 51.36
6887171621	CCP15C76	165°F	74°C	Chrome	\$ 78.48
6887171618	CCP15W76	135°F	57°C	White	\$ 30.58
6887171690	CCP15SP76	165°F	74°C	Specialty	\$ 51.36
MODEL CCP COVERPLATES (1/2" ADJ)					
6887161321	CCP0C76	135°F	57°C	Chrome	\$ 78.48
6887161318	CCP0W76	135°F	57°C	White	\$ 30.58
6887161390	CCP0SP76	135°F	57°C	Specialty	\$ 51.36
6887161621	CCP1C76	165°F	74°C	Chrome	\$ 78.48
6887161618	CCP1W76	165°F	74°C	White	\$ 30.58
6887161690	CCP1SP76	165°F	74°C	Specialty	\$ 51.36
6880100000	WRC	Requires Model RC1 Sprinkler Wrench			\$ 288.74

Notes:

Sprinklers and coverplates sold and packaged separately



Non-Ferrous

Part Number	Short Code	Temperature		Finish	List Price
MODEL F4FR-NF CONCEALED K5.6 (80) THREADS 1/2" (15MM) RA0212					
0613723299	F4FRNFW	135°F	57°C	White	\$ 182.65
0613213299	F4FRNFC	135°F	57°C	Chrome	\$ 182.65
0615723299	F4FRNF1W	155°F	68°C	White	\$ 182.65
0615213299	F4FRNF1C	155°F	68°C	Chrome	\$ 182.65

6880170000 WG4 Requires Model G4 Sprinkler Wrench \$ 287.62

F4FR-NF

- K-Factor = 5.6 (80)
- **SIN RA0212**
- See Bulletin 002



XL Commercial

- K-Factor = 5.6 (80)
- Pendent = SIN R4514
- HSW = SIN R4534
- See Bulletin 145

Part Number	Short Code	Temperature		Finish	List Price
MODEL XL PENDENT K5.6 (80) THREADS 1/2" (15MM) RA4514					
1212213299	XLQRPC	165°F	74°C	Chrome	\$ 138.45
1212723299	XLQRPW	165°F	74°C	White	\$ 138.45
MODEL XL HORIZONTAL K5.6 (80) THREADS 1/2" (15MM) RA4534					
1352213299	XLQRHC	165°F	74°C	Chrome	\$ 171.88
1352723299	XLQRHW	165°F	74°C	White	\$ 171.88
REQUIRED ESCUTCHEONS FOR MODEL XL FLAT					
6801210000	ZXFPC			Chrome	\$ 26.65
6801220000	ZXFPW			White	\$ 26.65
REQUIRED ESCUTCHEONS FOR MODEL XL CONICAL					
6801070000	ZXCPC			Chrome	\$ 26.65
6801080000	ZXCPW			White	\$ 26.65
REQUIRED ESCUTCHEONS FOR MODEL XL HSW					
6801120000	ZXCHC			Chrome	\$ 26.65
6801140000	ZXCHW			White	\$ 26.65
2-PIECE REQUIRED ESCUTCHEONS FOR MODEL XL PENDENT					
6801240000	ZX2PC			Chrome	\$ 32.74
6801250000	ZX2PW			White	\$ 34.15

6880160000	WZXP	Requires Model ZX (Pendent) Sprinkler Wrench	\$ 287.62
6880160010	WZXH	Requires Model ZX (Horizontal) Sprinkler Wrench	\$ 287.62