



F156 EC

- K-Factor = 5.6 (80)
- **SIN RA2745**
- See Bulletin 027



F1 LO EC PENDENT

- K-Factor = 8.0 (115)
- **SIN R1742**
- See Bulletin 117

Part Number	Short Code	Temperature		Finish	List Price
MODEL F156 EC PENDENT K5.6 (80) THREADS 1/2" (15MM) RA2745					
AB131130R9	F56ECP0B	135°F	57°C	Bronze	\$ 46.32
AB132130R9	F56ECP0C	135°F	57°C	Chrome	\$ 46.32
AB138730R9	F56ECP0W	135°F	57°C	White	\$ 49.96
AB151130R9	F56ECP1B	155°F	68°C	Bronze	\$ 46.32
AB152130R9	F56ECP1C	155°F	68°C	Chrome	\$ 46.32
AB158730R9	F56ECP1W	155°F	68°C	White	\$ 49.96
MODEL F1 LO EC PENDENT K8.0 (115) THREADS 3/4" (20MM) R1742					
AJ13113998	FCEP0LB	135°F	57°C	Bronze	\$ 50.54
AJ13213998	FCEP0LC	135°F	57°C	Chrome	\$ 50.54
AJ13873998	FCEP0LW	135°F	57°C	White	\$ 54.31
AJ15113998	FCEP1LB	155°F	68°C	Bronze	\$ 50.54
AJ15213998	FCEP1LC	155°F	68°C	Chrome	\$ 50.54
AJ15873998	FCEP1LW	155°F	68°C	White	\$ 54.31
MODEL F1 RECESSED ESCUTCHEONS & COLLAR ASSEMBLY					
6800630001	GF1B	1/2" (15mm)		Bronze	\$ 17.68
6800600001	GF1C	1/2" (15mm)		Chrome	\$ 9.54
6800640001	GF1W	1/2" (15mm)		White	\$ 9.54
6801030000	GF1LB	3/4" (20mm)		Bronze	\$ 17.68
6801000000	GF1LC	3/4" (20mm)		Chrome	\$ 9.54
6801040000	GF1LW	3/4" (20mm)		White	\$ 9.54
6800930000	GF1MB	10mm		Bronze	\$ 17.66
6800900000	GF1MC	10mm		Chrome	\$ 9.41
6800940003	GF1MW	10mm		White	\$ 9.41
MODEL F2 RECESSED ESCUTCHEONS & COLLAR ASSEMBLY					
6800830000	GF2B	1/2" (15mm)		Bronze	\$ 17.68
6800800000	GF2C	1/2" (15mm)		Chrome	\$ 9.54
6800840000	GF2W	1/2" (15mm)		White	\$ 9.54
6800880004	GF2LB	3/4" (20mm)		Bronze	\$ 17.68
6800880001	GF2LC	3/4" (20mm)		Chrome	\$ 9.54
6800880005	GF2LW	3/4" (20mm)		White	\$ 9.54
6880050100	WW2	Requires Model W2 Sprinkler Wrench			\$ 95.50
6880060000	WGFR	For Recessed Use Model GFR2 Wrench			\$ 288.74



F156-300 SREC

- K-Factor = 5.6 (80)
- **SIN RA2945**
- See Bulletin 029
- 300 PSI



F1-300 EC PENDENT

- K-Factor = 8.0 (115)
- **SIN R5842**
- See Bulletin 158
- 300 PSI

Part Number	Short Code	Temperature		Finish	List Price
MODEL F156 EC PENDENT K5.6 (80) THREADS 1/2" (15MM) RA2945 300PSI					
AH13113299	FEC3P0B3	135°F	57°C	Bronze	\$ 45.22
AH13213299	FEC3P0C3	135°F	57°C	Chrome	\$ 49.58
AH13873299	FEC3P0W3	135°F	57°C	White	\$ 53.31
AH15113299	FEC3P1B3	155°F	68°C	Bronze	\$ 45.22
AH15213299	FEC3P1C3	155°F	68°C	Chrome	\$ 49.58
AH15873299	FEC3P1W3	155°F	68°C	White	\$ 53.31
MODEL F1 LO EC PENDENT K8.0 (115) THREADS 3/4" (20MM) R5842 300 PSI					
AH13113998	FEC3P0LB3	135°F	57°C	Bronze	\$ 49.58
AH13213998	FEC3P0LC3	135°F	57°C	Chrome	\$ 53.89
AH13873998	FEC3P0LW3	135°F	57°C	White	\$ 57.69
AH15113998	FEC3P1LB3	155°F	68°C	Bronze	\$ 49.58
AH15213998	FEC3P1LC3	155°F	68°C	Chrome	\$ 53.89
AH15873998	FEC3P1LW3	155°F	68°C	White	\$ 57.69
MODEL F1 RECESSED ESCUTCHEONS & COLLAR ASSEMBLY					
6800630001	GF1B	1/2" (15mm)		Bronze	\$ 17.68
6800600001	GF1C	1/2" (15mm)		Chrome	\$ 9.54
6800640001	GF1W	1/2" (15mm)		White	\$ 9.54
6801030000	GF1LB	3/4" (20mm)		Bronze	\$ 17.68
6801000000	GF1LC	3/4" (20mm)		Chrome	\$ 9.54
6801040000	GF1LW	3/4" (20mm)		White	\$ 9.54
6880050100	WW2	Requires Model W2 Sprinkler Wrench			\$ 95.50
6880060000	WGFR	For Recessed Use Model GFR2 Wrench			\$ 288.74



G-EC4 HSW

- K-Factor = 8.0 (115)
- SIN R1267
- See Bulletin 112

Part Number	Short Code	Temperature		Finish	List Price
MODEL G-EC4 HORIZONTAL K8.0 (115) THREADS 3/4" (20MM) R1267					
5413113698	GEC4LB	135°F	57°C	Bronze	\$ 61.84
5413213698	GEC4LC	135°F	57°C	Chrome	\$ 67.19
MODEL F1 RECESSED ESCUTCHEONS & COLLAR ASSEMBLY					
6801030000	GF1LB	3/4" (20mm)		Bronze	\$ 17.68
6801000000	GF1LC	3/4" (20mm)		Chrome	\$ 9.54
6801040000	GF1LW	3/4" (20mm)		White	\$ 9.54
6800970000	GF1LSP	3/4" (20mm)		Specialty	\$ 34.68

6880050100	WW2	Requires Model W2 Sprinkler Wrench	\$ 95.50
6880060000	WGFR	For Recessed Use Model GFR2 Wrench	\$ 288.74



GFR VELO-ECOH

- K-Factor = 14 (200)
- **SIN R6553**
- See Bulletin 165

Part Number	Short Code	Temperature		Finish	List Price
MODEL GFR VELO-ECOH UPRIGHT K14 (200) THREADS 3/4" (20MM) R6553					
0116114598	GFRUV1B	165°F	74°C	Bronze	\$ 107.33
0116214598	GFRUV1C	165°F	74°C	Chrome	\$ 111.58
0121114598	GFRUV2B	212°F	100°C	Bronze	\$ 107.33
0121214598	GFRUV2C	212°F	100°C	Chrome	\$ 111.58

6880070000 WH Requires Model H Sprinkler Wrench \$ 115.72

Part Number	Short Code	Temperature		Finish	List Price
MODEL GFR VELO-ECOH PENDENT K14 (200) THREADS 3/4" (20MM) R6043					
FB16114598	GFRPV1B	165°F	74°C	Bronze	\$ 80.59
FB16214598	GFRPV1C	165°F	74°C	Chrome	\$ 83.83
FB16874598	GFRPV1W	165°F	74°C	White	\$ 87.43
FB21114598	GFRPV2B	212°F	100°C	Bronze	\$ 80.59
FB21214598	GFRPV2C	212°F	100°C	Chrome	\$ 83.83
FB21874598	GFRPV2W	212°F	100°C	White	\$ 87.43

6880070000 WH Requires Model H Sprinkler Wrench \$ 115.72


6880070100 WXLO Requires Model XLO Sprinkler Wrench for Recessing \$ 151.67

*Recessing available.



GFR VELO ECOH

- K-Factor = 14 (200)
- **SIN R6043**
- See Bulletin 160

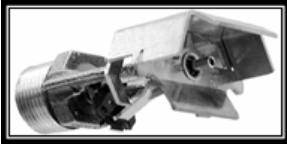

MBEC-14

- K-Factor = 14 (200)
- **SIN R6932**
- See Bulletin 169

Part Number	Short Code	Temperature		Finish	List Price
MODEL MB-EC 14 HORIZONTAL K14 (200) THREADS 3/4" (20MM) R6932					
4816114597	MB1B	165°F	74°C	Bronze	\$ 86.03
4816214597	MB1C	165°F	74°C	Chrome	\$ 98.69
4816874597	MB1W	165°F	74°C	White	\$ 98.69
4821114597	MB2B	212°F	100°C	Bronze	\$ 86.03
4821214597	MB2C	212°F	100°C	Chrome	\$ 98.69
4821874597	MB2W	212°F	100°C	White	\$ 98.69
6880070000	WH	Requires Model H Sprinkler Wrench			\$ 115.72