

AIR COMPRESSORS | GAST MFG



Description	System Capacity	Part Number	Short Code	List Price
GAST AIR COMPRESSORS - BARE				
1/6 HP, 115-60-1, 1LAA-10-M100X	90 Gallons	6999990904	16A	\$1,921.41
1/4 HP, 115-60-1, 2LAF-10-M200X	150 Gallons	6999991538	14A	\$2,033.52
1/3 HP, 115-60-1, 3LBA-33-M300X	180 Gallons			\$ Call
1/2 HP, 115-60-1, 4LCB-10-M450X	300 Gallons	6999991518	12A	\$3,019.07
3/4 HP, 115/208-230-60-1, 5LCA-23-550NGX	400 Gallons			\$ Call
1 HP, 115/230-60-1, 6LCF-10-M616NEX	600 Gallons	6999991315	1A	\$3,780.36
1.5 HP, 115/230-60-1, 7LDE-10-M700X	800 Gallons	6702000150	112A	\$6,773.36
2 HP, 115/230-60-1, 8LDF-10-M850X	1000 Gallons			\$ Call

*Above models can be outfitted with accessories of your own such as pressure switch, check valve, air tank and can also be used with a Model B Pressure Maintenance Device to set supervisory pressure settings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power



Description	System Capacity	Part Number	Short Code	List Price
GAST ROCKING PISTON AIR COMPRESSORS WITH SURGE TANK, CHECK VALVE AND DIGITAL PRESSURE SWITCH				
87R-100S, 1/2 HP, 120V, 60HZ	See below	6990026704	G87R	\$ 4,823.21

*Above model features a digital pressure switch with adjustable pressure settings from 10 PSI up to 50 PSI and with a 5 PSI differential. Ultra quiet compressor and fast install Unistrut rail design for mounting to a riser. All mounting hardware and airline hose connector included. Use adjustable pressure settings for system pressure, or with a Model A Pressure Maintenance Device to set supervisory pressure settings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power. System Capacity (gallons) ratings: 10 PSI Cut-out = 1,350 Gallons; 18 PSI Cut-out = 725 Gallons; 40 PSI Cut-out = 300 Gallons. Consult factory for more capacity ratings if needed



Description	System Capacity	Part Number	Short Code	List Price
GAST ROCKING PISTON AIR COMPRESSORS WITH SURGE TANK, CHECK VALVE AND DIGITAL PRESSURE SWITCH				
2 HP, 230-60-1 120R-200S RISER MOUNT		6990027243	200S	\$ 8,577.50
2 HP, 230-60-1, 120R-200T	20 GALLONS	6990027244	200T	\$ 9,328.36

*Above models feature a digital pressure switch with factory set for 125 PSI cut-out. System capacity gallon ratings: 940 @ 40 PSI; 2259 @ 18 PSI. Riser mount model features fast install channel strut rail design for mounting. All mounting hardware and airline hose connector included.



Description	Part Number	Short Code	List Price
UL LISTED - GAST AIR COMPRESSORS WITH CHECK VALVE AND PRESSURE SWITCH			
1/6 HP, UL 115-60-1, 1LAA-46S-M100GX	6999995064	16PAU	\$ 2,789.64
1/4 HP, UL 115-60-1, 2LAF-46S-M200EX	6999995080	14PAU	\$ 3,102.50
1/3 HP, UL 115-60-1, 3LBA-46S-M300AX	6999995134	13PAU	\$ 3,436.21
1/2 HP, UL 115-60-1, 4LCB-46S-M450GX	6999995098	12PAU	\$ 3,936.79
3/4 HP, UL 115/208-230-60-1, 5LCA-46S-M550GX	6999995066	34PAU	\$ 4,249.64
1 HP, UL 115/230-60-1, 6LCF-46S-M616NEX	6999994852	1PAU	\$ 4,791.93
1.5 HP, UL 115/230-60-1, 7LDE-46S-M750X	6999995067	112PAU	\$ 7,743.21
2 HP, UL 115/230-60-1, 8LDF-46S-M850X	6990008225	2PAU	\$ 10,558.93

*Above models can be mounted to a riser using a Gast mounting bracket. Pressure switch is factory set with 40 PSI cut-in and 50 PSI cut-out pressure setting. Cut-in pressure cannot be adjusted below 30 PSI. On/Off differential of 10 PSI cannot be changed (example: if cut-in pressure is lowered to 30 PSI, then the cut-out pressure will be 40 PSI and cannot be changed) These compressors are rated for 50 PSI max pressure. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

AIR COMPRESSORS | GAST MFG



Description	System Capacity	Part Number	Short Code	List Price
UL-LISTED GAST AIR COMPRESSORS WITH CHECK VALVE AND PRESSURE SWITCH				
GAST,#1LAA-46S-M100GX,UL2125,1/6HP		6999995064	16PAU	\$ 2,789.64
GAST,#2LAF-46S-M200EX,UL2125,1/4HP		6999995080	14PAU	\$ 3,102.50
GAST,#3LBA-10-M300AX		6999991276		\$ 2,654.07
GAST,#3LBA-46S-M300AX,UL2125,1/3HP		6999995134	13PAU	\$ 3,436.21
GAST,#4LCB-46S-M450GX,UL2125,1/2HP		6999995098	12PAU	\$ 3,936.79
GAST,#5LCA-10-M550NGX		6990005550		\$ 3,227.64
GAST,#5LCA-46S-M550GX,UL1450,3/4HP		6999995066	34PAU	\$ 4,249.64
GAST,#6LCF-46S-M616NEX,UL2125,1HP		6999994852	1PAU	\$ 4,791.93
GAST,#7LDE-46S-M750X,UL2125,1-1/2HP		6999995067	112PAU	\$ 7,743.21
GAST,#8LDF-46S-M850X,UL2125,2HP W/O TANK		6990008225	2PAU	\$ 10,558.93



Description	System Capacity	Part Number	Short Code	List Price
NON UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 100 PSI				
1/6 HP, 115-60-1, 1HAB-11T-M100X,2 GAL	80 Gallons	6999991027	16TA	\$ 3,780.36
3/4 HP, 115/230-60, 55HCD-11T-M550NGX, 20 GAL	340 Gallons			\$ Call
1.5 HP, 230-60-1, 7HDD-11TA-M750X, 30 GAL	660 Gallons	6990013330		\$ 17,655.15

*Above models have stored air pressure at 100 PSI. Cut-in pressure of 80 PSI (70 PSI on the 1HAB only) Cut-out pressure of 100 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings. Compressor will cycle less and last longer than compressors with lower max pressure ratings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power (if no number shown after 60Hz it is 1-phase power)



Description	System Capacity	Part Number	Short Code	List Price
UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED				
GAST,#1LAA-46T-M100GX TANK,1/6HP,UL2125		6999995091	16TAU	\$ 4,301.79
GAST,#2LAF-46T-M200EX TANK,1/4HP,UL2125		6999995111	14TAU	\$ 5,970.36
GAST,#4LCB-46T-M450GX TANK,1/2HP,UL2125		6999995114	12TAU	\$ 7,795.36
GAST,#5LCA-46T-M550GX TANK,3/4HP,UL2125		6999995110	34TAU	\$ 7,868.36
GAST,#6LCF-46T-M616NEX TANK,1HP,UL2125		6999995136	1TAU	\$ 8,108.21
GAST,#8HDM-11TD-M853,3 PHASE		6990014520		\$ 18,119.64
GAST,#8LDF-46T-M850X,UL2125,2HP		6990011326	2TAU	\$ 16,398.93

Description	System Capacity	Part Number	Short Code	List Price
UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 50 PSI				
1/6HP, UL 115-60-1, 1LAA-46T-M100GX, 2GAL	90 Gallons	6999995091	16TAU	\$ 4,301.79
1/4HP, UL 115-60-1, 2LAF-46T-M200EX, 12GAL	150 Gallons	6999995111	14TAU	\$ 5,970.36
1/3HP, UL 115-60-1, 3LBA-46T-M300AX, 12GAL	180 Gallons	6999993433	13TAU	\$ 6,825.50
1/2HP, UL 115-60-1, 4LCB-46T-M450GX, 20GAL	300 Gallons	6999995114	12TAU	\$ 7,795.36
3/4HP, 115/230-60-1, 5LCA-46T-M550GX, 20GAL	400 Gallons	6999995110	34TAU	\$ 7,868.36
1HP, 115/230-60-1, 6LCF-46T-M616NEX, 30GAL	600 Gallons	6999995136	1TAU	\$ 8,108.21
1.5HP, 115/230-60-1, 7LDE-46T-M750X, 30GAL	800 Gallons	6999995056	112TAU	\$ 12,300.50
2 HP, 115/230-60-1, 8LDF-46T-M850X, 30GAL	1000 Gallons	6990011326	2TAU	\$ 16,398.93

*Above models are UL Listed air tank compressors and have stored air pressure at 50 PSI. Cut-in pressure of 30 PSI and cut-out pressure of 50 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings if needed. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

AIR COMPRESSORS | GAST MFG



2x120R-90BQ6
model shown



120R-40MQ3 & 2x120R-40MQ6
metal cabinet models shown

Description	System Capacity (Gallons)	Part Number	Short Code	List Price
DRY AIR COMPRESSORS				
GAST,#1203560,120R-40BQ3 DRY AIR COMP	618	6990027863		\$27,609.64
GAST,#1206061,120R-40MQ3 DRY AIR COMP	618	6990027864		\$33,606.07
GAST,#1206330,2X120R-40MQ6 DRY AIR COMP	882	6990027866		\$47,841.07
GAST,#1203730,2X120R-90BQ6 DRY AIR COMP	932	6990027865		\$46,641.79

Description	System Capacity (Gallons)	Part Number	Short Code	List Price
UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 50 PSI				
1/6HP, UL 115-60-1, 1LAA-46T-M100GX, 2GAL	90	6999995091	16TAU	\$ 4,301.79
1/4HP, UL 115-60-1, 2LAF-46T-M200EX, 12GAL	150	6999995111	14TAU	\$ 5,970.36
1/3HP, UL 115-60-1, 3LBA-46T-M300AX, 12GAL	180	6999993433	13TAU	\$ 6,825.50
1/2HP, UL 115-60-1, 4LCB-46T-M450GX, 20GAL	300	6999995114	12TAU	\$ 7,795.36
3/4HP, 115/230-60-1, 5LCA-46T-M550GX, 20GAL	400	6999995110	34TAU	\$ 7,868.36
1HP, 115/230-60-1, 6LCF-46T-M616NEX, 30GAL	600	6999995136	1TAU	\$ 8,108.21
1.5HP, 115/230-60-1, 7LDE-46T-M750X, 30GAL	800	6999995056	112TAU	\$12,300.50
2 HP, 115/230-60-1, 8LDF-46T-M850X, 30GAL	1000	6990011326	2TAU	\$16,398.93

*Above models are UL Listed air tank compressors and have stored air pressure at 50 PSI. Cut-in pressure of 30 PSI and cut-out pressure of 50 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings if needed. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power



Description	Part Number	Short Code	List Price
GAST AIR COMPRESSOR - REPAIR KITS*			
K1022 FLOOR MOUNT KIT (87R)	6990026509	K1022	\$ 110.33
K263 REPAIR KIT, 3/4HP	6888000020	K263	\$ 499.84
K303 REPAIR KIT 1-1/2HP	6888000030	K303	\$ 803.63
AT670 MOUNTING BRACKETS,1/6-1 HP	6999990969	GMB	\$ 217.07
AT670A, MOUNTING BRACKET, 1.5-2 HP	6990007698	GMBL	\$ 466.68
SSP-87R6-01 SOUND SHIELD KIT	6990026510	SSP87R6	\$ 550.06

*Repair Kit Contains: Gaskets, Piston, Seals, Piston Rings, In/Out Valve Plates, Manifold Seals and Felts (for Filters). SSP-87R6-01 Sound Shield kit provides a retrofit kit of part for Gast 87R-110S compressor shown above and reduces sound levels up to 20%

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.



AIR COMPRESSORS | C-AIRE

Description	System Capacity	Part Number	Short Code	List Price
HEAVY DUTY - SINGLE PHASE - TANK MOUNTED				
S175-HD1-115 (115V, 1HP, 3 GALLON)	175 gallons	6990012386	C175	\$ 4,006.45
S265H-HD1-115 (115V, 1-1/2 HP, 3 GALLON)	265 gallons	6990012600	C265	\$ 4,080.40
S325H-HD1-115 (115V, 1-1/2 HP, 3 GALLON)	325 gallons	6990012601	C325	\$ 4,185.32
S500H-HD1-115 (115V, 1-1/2 HP, 30 GALLON)	500 gallons	6990012602	C500	\$ 6,397.19
S750H-HD1-230 (3HP,230V,30 GALLON H)	750 gallons	6990013997	C750	\$ 7,302.82
S900H-HD1-230 (5HP,230V,30 GALLON H)	900 gallons	6990013998	C900	\$ 7,468.33
S1300H-HD1-230S (5HP,230V,60 GALLON H)	1300 gallons	6990013999	C1300	\$ 12,619.56
S1700H-HD1-230S (7.5HP,230V,60 GALLON H)	1700 gallons	6990014000	C1700	\$ 13,344.82
STANDARD DUTY - SINGLE PHASE - TANK MOUNTED				
S300H-SD1-115 (1HP,115V,3 GALLON H)	300 gallons	6990013994	C300	\$ 3,405.48
RISER MOUNTED				
C-AIRE,#S280R-LD1-115P		7M99004812	C280R	\$ 2,896.17
C-AIRE,#S281R-LD1-115PD		7M99004813	C281R	\$ 4,266.37
				\$ Call

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.




**QRM RISER &
 TANK MOUNTED
 AIR
 COMPRESSORS**

• See Bulletin 256

NEW


Description	Part Number	Short Code	List Price
QRM2 AIR COMPRESSORS -- TANKLESS W/CHECK VALVE & PRESSURE SWITCH			
RASCO AIR, QRM25115 1/4HP, 115, TANKLESS	6872000001		\$3,480.00
RASCO AIR, QRM2-25220 1/4HP, 220, TANKLESS	6872000002		\$3,438.57
RASCO AIR, QRM2-50115 1/2HP, 115, TANKLESS	6872000005		\$4,308.57
RASCO AIR, QRM2-50220 1/2HP, 220, TANKLESS	6872000006		\$4,495.00
RASCO AIR, QRM2-25220-50HZ, 1/4, 220, TNKLSS	6872000011		\$3,438.57
RASCOAIR, QRM2-50220-50HZ, 1/2, 220, TNKLSS	6872000013		\$4,495.00
RASCO AIR, QRM2-25115-4050 1/4HP, 115, TL	6872000040		\$3,174.46
RASCO AIR, QRM2-50115-4050 1/2HP, 115, TL	6872000042		\$4,308.57
RASCO AIR, QRM2-25220-4050 1/4HP, 220, TL	6872000041		\$3,438.57
RASCO AIR, QRM2-50220-4050 1/2HP, 220, TL	6872000043		\$4,495.00
QRM2 AIR COMPRESSORS - TANK MOUNTED			
RASCO AIR, QRM2-25115T 1/4HP, 115, TANK	6872000003		\$5,028.39
RASCO AIR, QRM2-25220T 1/4HP, 220, TANK	6872000004		\$5,380.54
RASCO AIR, QRM2-50115T 1/2HP, 115, TANK	6872000007		\$5,722.32
RASCO AIR, QRM2-50220T 1/2HP, 220, TANK	6872000008		\$5,965.71
RASCO AIR, QRM2-100115T, 1 HP, 115, TANK	6872000009		\$8,290.89
RASCO AIR, QRM2-100220T, 1 HP, 220, TANK	6872000010	1QRM220T	\$8,047.50
RASCO AIR, QRM2-25220T-50HZ, 1/4, 220, TANK	6872000012		\$5,380.54
RASCO AIR, QRM2-50220T-50HZ, 1/2, 220, TANK	6872000014		\$5,965.71
RASCO AIR, QRM2-100220T-50HZ, 1, 220, TANK	6872000015		\$8,047.50
CONNECTION KITS			
Connection Kit, Tankless Compressor	650120011G	CKTL	\$1,200.00
Connection Kit, Tank Mounted Compressor	650120011H	CKTM	\$1,322.95
FLEX HOSE -- SOLD SEPARATELY			
			\$ Call

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

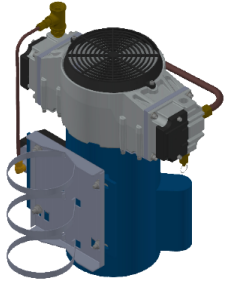

RRM RISER MOUNTED AIR COMPRESSOR

• See Bulletin 258

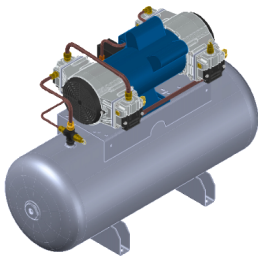

RTM TANK MOUNTED AIR COMPRESSOR

• See Bulletin 258

Description	Part Number	Short Code	List Price
RRM AIR COMPRESSORS - TANKLESS W/CHECK VALVE & PRESSURE SWITCH			
RASCO AIR,RRMA23016-2026,1/6HP,115/220V	6990027979		\$ 3,205.54
RASCO AIR,RRMA40033-2026,1/3HP,115/220V	6990027980		\$ 3,801.07
RASCO AIR,RRMA70050-2026,1/2HP,115/220V	6990027981		\$ 5,028.39
RASCO AIR,RRMA23016-4050,1/6HP,115,CP	6990027982		\$ 3,205.54
RASCO AIR,RRMA40033-4050,1/3HP,115,CP	6990027983		\$ 3,801.07
RASCO AIR,RRMA70050-4050,1/2HP,115,CP	6990027984		\$ 5,028.39
RTM AIR COMPRESSORS -- TANK MOUNTED			
RASCO AIR,RTMA25033-80100,1/3HP,115/220V	6990027985		\$ 5,882.86
RASCO AIR,RTMA36575-80100,3/4HP,115/220V	6990027986		\$ 8,430.71
RASCO AIR,RTMA550100-80100,1HP,115/220V	6990027987		\$ 10,502.14
RASCO AIR,RTMA915150-80100,1-1/2HP,1PH	6990027988		\$ 13,743.93
RASCO AIR,RTMA1100200-80100,2HP,1PH	6990027989		\$ 15,660.00
CONNECTION KITS			
Connection Kit, Tankless Compressor	650120011G	CKTL	\$ 1,200.00
Connection Kit, Tank Mounted Compressor	650120011H	CKTM	\$ 1,322.95
FLEX HOSE -- SOLD SEPARATELY			
Flex Hose, Stainless Steel, 1/2" x 30"			\$ Call

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

AIR COMPRESSORS | GENERAL AIR



Description	System Capacity	Part Number	Short Code	List Price
RISER MOUNTED				
GENERAL,#OLR12016AC,RISER MNT	125	6990027700	16PAGE	\$ 2,915.54
GENERAL,#OLR25033AC,RISER MNT	250	6990027704		\$ 3,630.18
GENERAL,#OLR32016AC-LP,RISER MNT	320	6990027707		\$ 3,153.75
GENERAL,#OLR40050AC,RISER MNT	365	6990027708	12PAGE	\$ 4,785.00
GENERAL,#OLR50075AC,RISER MNT	430	6990027867		\$ 5,888.66
GENERAL,#OLR55033AC-LP,RISER MNT	550	6990027714		\$ 3,744.11
GENERAL,#OLR615100AC,RISER MNT	615	6990027869		\$ 6,646.80
GENERAL,#OLR86050AC-LP,RISER MNT	860	6990027718		\$ 4,981.79
GENERAL,#OLR915150AC,RISER MNT	915	6990027719		\$ 8,332.32
GENERAL,#OLR99575AC-LP,RISER MNT	990	6990027722		\$ 5,308.04
GENERAL,#OLR1225200AC,RISER MNT	1225	6990027702		\$10,269.11

Notes:

Models above come with mounting bracket, 1/2" flexible air line hose and 1/2 threaded union.



Description	System Capacity	Part Number	Short Code	List Price
TANK MOUNTED				
GENERAL,#OLT12016AC,TANK MNT	125	6990027725		\$ 5,644.64
GENERAL,#OLT25033AC,TANK MNT	250	6990027730		\$ 6,488.75
GENERAL,#OLT40050AC,TANK MNT	365	6990027733		\$ 7,648.75
GENERAL,#OLT50075AC,TANK MNT	430	6990027871		\$ 7,969.82
GENERAL,#OLT600100AC,TANK MNT	615	6990027873		\$10,007.49
GENERAL,#OLT915150AC,TANK MNT	915	6990027748		\$12,863.57
GENERAL,#OLT1225200AC,TANK MNT	1225	6990027727		\$14,525.89

Notes:

Models above come with vibrations isolators and 1/2" flexible air line hose.



Description	System Capacity	Part Number	Short Code	List Price
DRY AIR PACS				
GENERAL,#DAP-500B,2HP,60HZ,3PHASE		6990004645		\$49,833.60
GENERAL,#DAP1000B,3PHASE,460V,60HZ		6990018930		\$53,688.94
GENERAL,#DAP2000B,3PHASE,460V,60HZ		6990006022		\$58,988.49

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

AIR COMPRESSORS | GENERAL AIR

Description	System Capacity	Part Number	Short Code	List Price
TANK MOUNTED LT PLUS SERIES				
GENERAL,#LT20033A-HP	185	6990026929		\$ 7,124.06
GENERAL,#LT29050A-HP	220	6990026939		\$ 7,158.86
GENERAL,#LT425100A-HP	345	6990026943		\$ 7,467.09
GENERAL,#LT620100A-HP,1HP,TANK MNT,1PH	620	6990026945		\$ 8,282.40
GENERAL,#LT900150A-HP,1.5HP,TANK MNT,1PH	900	699004805		\$ 8,526.00
GENERAL,#LT1300300A-HP	1080	6990026917		\$ 9,420.86
GENERAL,#LT1600300A-HP	1200	6990026919		\$ 14,939.14
GENERAL,#LT2000500A-HP	1900	6990026923		\$ 15,774.34
GENERAL,#LT2500500A-HP	2400	6990026933		\$ 16,413.17

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.