



## FP PUSH-ON/THREAD-OFF ESCUTCHEONS

Description	Part Number	Short Code	List Price
<b>MODEL FP PUSH-ON/THREAD-OFF ESCUTCHEONS</b>			
1/2" Chrome	6801412100	FPC	S\$ 32.19
1/2" White	6801417200	FPW	S\$ 32.19
1/2" Stainless Steel	6801411000	FPSS	S\$ 147.45
3/4" Chrome	6801402100	FPLC	S\$ 32.19
3/4" White	6801407200	FPLW	S\$ 32.19
3/4" Stainless Steel	6801401000	FPLSS	S\$ 147.45
<b>MODEL F1 RECESSED ESCUTCHEONS &amp; COLLAR ASSEMBLY</b>			
1/2" Brass	6800630001	GF1B	S\$ 30.93
1/2" Chrome	6800600001	GF1C	S\$ 16.69
1/2" White	6800640001	GF1W	S\$ 16.69
1/2" Stainless Steel	6800610010	GF1SS	S\$ 98.30
3/4" Brass	6801030000	GF1LB	S\$ 30.93
3/4" Chrome	6801000000	GF1LC	S\$ 16.69
3/4" White	6801040000	GF1LW	S\$ 16.69
3/4" Stainless Steel	6800970010	GF1LSS	S\$ 98.30
<b>MODEL F1 ESCUTCHEON ONLY</b>			
Brass	6800430000	BZESCF1	S\$ 23.59
Chrome Bright	6800400000	CBESCF1	S\$ 10.04
White	6800440000	WHESCF1	S\$ 10.04
<b>MODEL F1/F2 COLLAR ONLY</b>			
1/2" Brass	6800530000	B2COLLAR12	S\$ 18.47
1/2" Chrome Bright	6800500000	CBCOLLAR12	S\$ 15.15
1/2" White	6800540000	WHCOLLAR12	S\$ 15.15
3/4" Brass	6800560004	B2COLLAR34	S\$ Call
3/4" Chrome Bright	6800560001	CBCOLLAR34	S\$ 15.15
3/4" White	6800551003	WHCOLLAR34	S\$ 15.15
<b>ESCUTCHEON EXTENDER RING</b>			
Chrome	6814002100	EERC	S\$ 21.43
White	6814001500	EERW	S\$ 22.85
<b>MODEL F1 OR F2 EXTENDER RINGS</b>			
4-1/2" Chrome	6814002100	EERC	S\$ 21.43
4-1/2" White	6814001500	EERW	S\$ 22.85
5-1/2" Chrome	6814042100	EERC5	S\$ 21.43
5-1/2" White	6814041500	EERW5	S\$ 22.85
<b>FP / G5 / G4 / RFC / CCP / SWC COVERPLATE EXTENDER RINGS</b>			
4-1/2" Chrome	6814022100	G4ERC	S\$ 21.43
4-1/2" White	6814021800	G4ERW	S\$ 22.85
5-1/2" Chrome	6814032100	G4ERC5	S\$ 21.43
5-1/2" White	6814031800	G4ERW5	S\$ 22.85

<b>MODEL F2 RECESSED ESCUTCHEONS &amp; COLLAR ASSEMBLY</b>			
1/2" Brass	6800830000	GF2B	S\$ 30.93
1/2" Chrome	6800800000	GF2C	S\$ 16.69
1/2" White	6800840000	GF2W	S\$ 16.69
1/2" Stainless Steel	6800840010	GF2SS	S\$ 98.30
3/4" Brass	6800880004	GF2LB	S\$ 30.93
3/4" Chrome	6800880001	GF2LC	S\$ 16.69
3/4" White	6800880005	GF2LW	S\$ 16.69
3/4" Stainless Steel	6800880110	GF2LSS	S\$ 98.30
<b>ESCUTCHEON ONLY</b>			
Brass	6800730000	BZESCF2	S\$ 23.43
Chrome	6800700000	CBESCF2	S\$ 15.11
White	6800740000	WHESCF2	S\$ 15.11
<b>COLLAR ONLY</b>			
1/2" Brass	6800530000	B2COLLAR12	S\$ 18.47
1/2" Chrome	6800500000	CBCOLLAR12	S\$ 15.15
1/2" White	6800540000	WHCOLLAR12	S\$ 15.15
3/4" Brass	6800560004	B2COLLAR34	S\$ Call
3/4" Chrome	6800560001	CBCOLLAR34	S\$ 15.15
3/4" White	6800551003	WHCOLLAR34	S\$ 15.15

### Notes:

All SS Escutcheons are Type 316 Stainless Steel.  
 Other escutcheon finishes are available upon request.



**B One Piece**



**C One Piece**



**HB Two Piece**

**ESCUTCHEONS (CONT.)**

- Sprinkler Accessories

**F1S ESCUTCHEON**



**F2S ESCUTCHEON**

- See Bulletin 204

Description	Size	Part Number	Short Code	List Price
<b>MODEL B ONE PIECE TYPE 1/2"</b>				
Bronze	1/2"	6800110000	BB	S\$ 6.89
Chrome	1/2"	6800150000	BC	S\$ 4.73
White	1/2"	6800120000	BW	S\$ 5.32
Stainless Steel	1/2"	6800121002	BSS	S\$ 59.00
<b>MODEL B ONE PIECE TYPE 3/4"</b>				
Bronze	3/4"	6800080000	BLB	S\$ 7.27
Chrome	3/4"	6800070000	BLC	S\$ 5.09
White	3/4"	6800090000	BLW	S\$ 5.09
Stainless Steel	3/4"	6800091002	BLSS	S\$ 59.00
<b>MODEL C ONE PIECE TYPE 1/2"</b>				
Bronze	1/2"	6800340000	CBB	S\$ 52.50
Chrome	1/2"	6800350000	CC	S\$ 5.05
White	1/2"	6800380000	CW	S\$ 5.05
<b>MODEL HB TWO PIECE TYPE 1/2"</b>				
Bronze	1/2"	6800210000	HBB	S\$ 12.01
Chrome	1/2"	6800270000	HBC	S\$ 10.81
White	1/2"	6800200000	HBW	S\$ 11.20
<b>MODEL HB TWO PIECE TYPE 3/4"</b>				
Bronze	3/4"	6800220000	HBLB	S\$ 12.39
Chrome	3/4"	6800240000	HBLC	S\$ 11.20
White	3/4"	6800250000	HBLW	S\$ 12.01
<b>TWO PIECE RECESSED — MODEL F1S</b>				
Chrome	1/2" (15mm)	6801752100	F1SC	S\$ 29.69
White	1/2" (15mm)	6801758700	F1SW	S\$ 29.69
Chrome	3/4" (20mm)	6801762100	F1SLC	S\$ 29.69
White	3/4" (20mm)	6801768700	F1SLW	S\$ 29.69
<b>MODEL F2S TWO PIECE RECESSED ESCUTCHEONS</b>				
Chrome	1/2" (15mm)	6801772100	F2SC	S\$ 29.69
White	1/2" (15mm)	6801778700	F2SW	S\$ 29.69
Chrome	3/4" (20mm)	6801782100	F2SLC	S\$ 29.69
White	3/4" (20mm)	6801788700	F2SLW	S\$ 29.69

**NEW**



**SURE-OFF TESTER**

- See Bulletin 277

Description	Part Number	Short Code	List Price
<b>PRESSURE TESTER</b>			
Sure-Off Tester 1"	6501220000	SURE	S\$ 2,414.24
Sure-Off Tester 1 1/4 - 1 1/2"	6501220002	SURE125	S\$ 2,414.24
Sure-Off Tester 2"	6501220003	SURE2	S\$ 2,414.24
Drill & Collar Assembly	6888000011		S\$ 326.36
Guide Bushing, Drill, Reducer	94905000		S\$ 108.12

The simple way to determine if the system you are about to work on has been shut-off and drained!

+44.1342.316800  
 www.reliablesprinkler.com

## Sprinkler Accessories

Description	Part Number	Short Code	List Price
<b>SPRINKLER GUARDS &amp; WATER SHIELD/GUARD ASSEMBLY</b>			
C1,GUARD,SU,SP,HORIZONTAL,ZINC,FM ONLY	6802251400	GC1	S\$ 16.91
C1,GUARD,SU,SP,HORIZONTAL,SS,FM ONLY	6802251000	GC1SS	S\$ 168.92
C2,GUARD,DRY PENDENTS,UL/FM	6802201400	GC2	S\$ 23.45
C3,GUARD,SHIELD,UPRIGHT-I,ZINC,UL/FM	6802501400	GC3	S\$ 34.61
C5,GUARD/SHIELD KIT,SP-I,1/2,ZINC,FM	6802611412	GC51	S\$ 48.36
C5,GUARD/SHIELD KIT,SP-I,3/4,ZINC,FM	6802611434	GC53	S\$ 48.36
D1,GUARD,SU/SP/HORIZONTAL,UL/FM ZINC	6802251410	GD1	S\$ 23.20
D3,GUARD/SHIELD KIT,SU-I,ZINC,UL ONLY	6802501410	GD3	S\$ 27.43
D5,GUARD/SHIELD KIT,SP-I,1/2,ZINC,UL	6802631412	GD51	S\$ 52.68
D5,GUARD/SHIELD KIT,SP-I,3/4,ZINC,UL	6802631434	GD53	S\$ 52.68
D4,GUARD/SHIELD KIT,SP-I,1/2,ZINC,UL	6802621412	GD41	S\$ 59.03
D4,GUARD/SHIELD KIT,SP-I,3/4,ZINC	6802621434	GD43	S\$ 59.03
D-7 for use w/ GL112 Upright Intermediate	6802611614	GD7	S\$ 27.43
D-8 for use w/ GL112 & GXLO Pendent	6802251714	GD8	S\$ 23.20
D-9 for use w- GL112 & GXLO Pendent Intermediate	6802621714	GD91	S\$ 52.68
D-6 for use w/ GXLO Upright Intermediate	6802611514	GD6	S\$ 26.04
F-6,GUARD/SHIELD KIT,3/4 NPS,ZINC	68026A1434	GF63	S\$ 56.00
F-1,GUARD,ZINC	6802651400	GF1	S\$ 23.20
F-2,GUARD,ZINC	6802661400	GF2	S\$ 49.00
F-3,GUARD,SHIELD	6802671400	GF3	S\$ 49.00
F-7,GUARD,ZINC	6802701400	GF7	S\$ 49.00
F-8,GUARD/SHIELD KIT,1/2 NPS,ZINC	68026B1412	GF81	S\$ 56.00
F-8,GUARD/SHIELD KIT,3/4 NPS,ZINC	68026B1434	GF83	S\$ 56.00
22 - (guard only) for use w/ HL22 ESFR	6802641422	G22	S\$ 52.50
25 - (guard only) for use w/ N25 ESFR	6802641425	G25	S\$ 52.50
D14,GUARD KIT,ZINC,SP,FM P22/P25	6802622514	GD14	S\$ 52.50
<b>RELIABLE MODEL RHB1 SPARE SPRINKLER STORAGE CABINET</b>			
RASCO,RHB1 HEADBOX 3 COUNT	7M99005006	RHB3	S\$ 94.59
RASCO,RHB1 HEADBOX 6 COUNT	7M99005007	RHB6	S\$ 144.59
RASCO,RHB1 HEADBOX 6 COUNT ESFR	7M99005008	RHB6E	S\$ 175.68
RASCO,RHB1 HEADBOX 12 COUNT	7M99005009	RHB12	S\$ 160.81
RASCO,RHB1 HEADBOX 24 COUNT	7M99005010	RHB24	S\$ 248.65
RASCO,RHB1 HEADBOX 36 COUNT	7M99005011	RHB36	S\$ 344.59
<b>A3 EMERGENCY CABINETS FOR RECESSED, CONCEALED &amp; ZX SPK</b>			
12 Capacity	6803200000	A312CAB	S\$ 779.61

## Sprinkler Accessories

Description	Part Number	Short Code	List Price
<b>MODEL F SERIES SPRINKLER GUARDS &amp; WATER SHIELD/GUARD ASSEMBLY</b>			
F-1,GUARD,ZINC	6802651400	GF1	S\$ 23.20
F-2,GUARD,ZINC	6802661400	GF2	S\$ 49.00
F-3,GUARD,SHIELD	6802671400	GF3	S\$ 49.00
F-7,GUARD,ZINC	6802701400	GF7	S\$ 49.00
F-5,GUARD/SHIELD KIT,1/2 NPS,ZINC	6802691412	GF51	S\$ 56.00
F-6,GUARD/SHIELD KIT,3/4 NPS,ZINC	68026A1434	GF63	S\$ 56.00
F-8,GUARD/SHIELD KIT,1/2 NPS,ZINC	68026B1412	GF81	S\$ 56.00
F-8,GUARD/SHIELD KIT,3/4 NPS,ZINC	68026B1434	GF83	S\$ 56.00
<b>MODEL S WATER SHIELDS</b>			
MODEL S-1 SHIELD,3.25,1/2-14NPS, GALV	88709001	S1SHIELD	S\$ 20.08
MODEL S-2 SHIELD,3.25,3/4-14NPS, GALV	88709002	S2SHIELD	S\$ 20.08
MODEL S-3 SHIELD,3.75,3/4-14NPS, GALV	88709003	S3SHIELD	S\$ 20.08
MODEL S-5 SHIELD,4.5,1"NPS,GALV	887G9010	S5SHIELD	S\$ 20.08

**Notes:**

For additional info see Bulletin 208



Description	Part Number	Short Code	List Price
<b>WRENCHES</b>			
WRENCH,DS56	6880130002	WDS56	\$S\$350.64
WRENCH,F3R,DRY	6880130001	WF3R	\$S\$264.92
WRENCH,FC,CONCEALED	6880170020	WFC	\$S\$503.31
WRENCH,G4,CONCEALED,ADJ,SP	6880170000	WG4	\$S\$498.69
WRENCH,G6 HSW SOCKET	6880101010	WG6	\$S\$498.69
WRENCH, W8, RFC PLASTIC SERVICE WRENCH	6880103000	W8	\$S\$312.09
WRENCH,GFR2,RECESSED,CONCEALED,SP	6880060000	WGFR	\$S\$500.64
WRENCH,H,XLO/GL112,BLUE	6880070000	WH	\$S\$200.65
WRENCH,J1,SPKR J112,J14,J17,ZINC.	6880090000	WJ1	\$S\$200.65
WRENCH,W13	6880108000	W13	\$S\$237.66
WRENCH,W14	6880108100	W14	\$S\$237.66
WRENCH,W15	6880108200	W15	\$S\$237.66
WRENCH,N,RECESSED	6880170030	WN	\$S\$498.69
WRENCH,RC1 SOCKET,RECESSED	6880100000	WRC	\$S\$500.64
WRENCH,RJ,J112/J112 REC CHROME	6880170032	WRJ	\$S\$498.69
WRENCH,W2(PENDENT,UPRIGHT,HSW)	6880050100	WW2	\$S\$165.58
WRENCH W3 FOR WRENCH-ABLE PROTECTIVE CAP	6880100110	W3	\$S\$503.31
WRENCH,W4,RECESSED,CONCEALED	6880100120	WW4	\$S\$500.64
WRENCH,W5,HL-22,N25,N252,TNL280,P22/25	6880050105	WW5	\$S\$200.65
WRENCH,XLO2,REC,CONCEALED SP	6880070100	WXLO	\$S\$262.96
WRENCH,XL,ZX,HORIZONTAL	6880160010	WZXH	\$S\$498.69
WRENCH,XL,ZX,PENDENT	6880160000	WZXP	\$S\$498.69
<b>VALVE WRENCHES &amp; VALVE SEAT WRENCHES</b>			
2-1/2" & 3" Model E Alarm Valve	6881603000		\$S\$360.38
4" Model E Alarm Valve	6881240000	W4DV	\$S\$506.47
6" Model E Alarm Valve	6881260000	W6DV	\$S\$543.49
8" Model E Alarm Valve	6881280000	W8AV	\$S\$582.43
2-1/2" Model A & 4" Model D Dry Pipe Valves	6881340000	W4DPV	\$S\$358.42
6" Model D Dry Pipe Valve	6881360000	W6DPV	\$S\$389.59
4" Model B & BX Deluge Valve	6881240000	W4DV	\$S\$506.47
6" Model B & BX Deluge Valve	6881260000	W6DV	\$S\$543.49
2" Model FX Dry Pipe Valve	6881702000	W2FX	\$S\$506.47
2-1/2" and 3" Model FX Dry Pipe Valves	6881703000	W3FX	\$S\$506.47
4" Model FX Dry Pipe Valve	6881704000	W4FX	\$S\$506.47
6" Model FX Dry Pipe Valve	6881706000	W6FX	\$S\$506.47

**Notes:**

Each sprinkler bulletin will show required wrench

**WRENCHES**

- See Bulletin 205

## PRINTED COVERPLATES


• See Bulletin 203



Slate Grey



Warm Maple

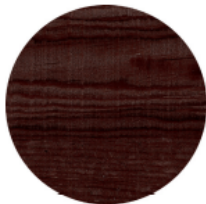

Dark Walnut



Silver Birch

**Note: Please see Bulletin 203 for additional finishes**

Part Number	Short Code	Temperature		Finish	List Price
<b>MODEL G6 PRINTED COVERPLATES</b>					
688721139A		135°F	57°C	Custom Ink	S\$ 85.12
688721139B		135°F	57°C	White Wash	S\$ 85.12
688721139C		135°F	57°C	Silver Birch	S\$ 85.12
688721139D		135°F	57°C	Beige Birch	S\$ 85.12
688721139E		135°F	57°C	Weathered Grey	S\$ 85.12
688721139F		135°F	57°C	Slate Grey	S\$ 85.12
688721139G		135°F	57°C	Golden Pine	S\$ 85.12
688721139H		135°F	57°C	Red Oak	S\$ 85.12
688721139J		135°F	57°C	Red Cherry	S\$ 85.12
688721139K		135°F	57°C	Warm Maple	S\$ 85.12
688721139M		135°F	57°C	Dark Walnut	S\$ 85.12
688721139N		135°F	57°C	Espresso	S\$ 85.12
688721139P		135°F	57°C	Rustic Beige	S\$ 85.12
<b>MODEL RFS42 PRINTED COVERPLATES</b>					
688723139A		135°F	57°C	Custom Ink	S\$ 85.91
688723139B		135°F	57°C	White Wash	S\$ 85.91
688723139C		135°F	57°C	Silver Birch	S\$ 85.91
688723139D		135°F	57°C	Beige Birch	S\$ 85.91
688723139E		135°F	57°C	Weathered Grey	S\$ 85.91
688723139F		135°F	57°C	Slate Grey	S\$ 85.91
688723139G		135°F	57°C	Golden Pine	S\$ 85.91
688723139H		135°F	57°C	Red Oak	S\$ 85.91
688723139J		135°F	57°C	Red Cherry	S\$ 85.91
688723139K		135°F	57°C	Warm Maple	S\$ 85.91
688723139M		135°F	57°C	Dark Walnut	S\$ 85.91
688723139N		135°F	57°C	Espresso	S\$ 85.91
688723139P		135°F	57°C	Rustic Beige	S\$ 85.91
<b>MODEL G5 PRINTED COVERPLATES</b>					
688727139A		135°F	57°C	Custom Ink	S\$ 79.81
688727139B		135°F	57°C	White Wash	S\$ 79.81
688727139C		135°F	57°C	Silver Birch	S\$ 79.81
688727139D		135°F	57°C	Beige Birch	S\$ 79.81
688727139E		135°F	57°C	Weathered Grey	S\$ 79.81
688727139F		135°F	57°C	Slate Grey	S\$ 79.81
688727139G		135°F	57°C	Golden Pine	S\$ 79.81
688727139H		135°F	57°C	Red Oak	S\$ 79.81
688727139J		135°F	57°C	Red Cherry	S\$ 79.81
688727139K		135°F	57°C	Warm Maple	S\$ 79.81
688727139M		135°F	57°C	Dark Walnut	S\$ 79.81
688727139N		135°F	57°C	Espresso	S\$ 79.81
688727139P		135°F	57°C	Rustic Beige	S\$ 79.81
688727169A		165°F	74°C	Custom Ink	S\$ 79.81
688727169B		165°F	74°C	White Wash	S\$ 79.81
688727169C		165°F	74°C	Silver Birch	S\$ 79.81
688727169D		165°F	74°C	Beige Birch	S\$ 79.81
688727169E		165°F	74°C	Weathered Grey	S\$ 79.81
688727169F		165°F	74°C	Slate Grey	S\$ 79.81
688727169G		165°F	74°C	Golden Pine	S\$ 79.81
688727169H		165°F	74°C	Red Oak	S\$ 79.81
688727169J		165°F	74°C	Red Cherry	S\$ 79.81
688727169K		165°F	74°C	Warm Maple	S\$ 79.81
688727169M		165°F	74°C	Dark Walnut	S\$ 79.81
688727169N		165°F	74°C	Espresso	S\$ 79.81
688727169P		165°F	74°C	Rustic Beige	S\$ 79.81



**MODEL G1  
 CONCEALED  
 REPLACEMENT  
 COVERPLATES**

Part Number	Short Code	Temperature		Finish	List Price
<b>MODEL G1 CONCEALED COVERPLATES - REQUIRED</b>					
6887001311	CG10B	135°F	57°C	Finished Bronze	S\$ 111.65
6887001321	CG10C	135°F	57°C	Chrome	S\$ 81.95
6887001372	CG10W	135°F	57°C	White	S\$ 81.95
6887001390	CG10SP	135°F	57°C	Special Paint	S\$ 120.12
6887001611	CG11B	165°F	74°C	Finished Bronze	S\$ 115.77
6887001621	CG11C	165°F	74°C	Chrome	S\$ 81.95
6887001672	CG11W	165°F	74°C	White	S\$ 81.95
6887001690	CG11SP	165°F	74°C	Special Paint	S\$ 120.12

6880100000      WRC      Requires Model RC1 Sprinkler Wrench      S\$ 500.64

**\*Model G1 Concealed Sprinkler is Obsolete.**  
**\*Please note special paint is subject to a paint set-up charge.**